



Connecting cable with socket

ADOGH050MSS0010E05

Article no longer available - archive entry



| Electrical data   |     |                   |
|-------------------|-----|-------------------|
| Operating voltage | [V] | < 30 AC / < 36 DC |


| Operating conditions |      |          |
|----------------------|------|----------|
| Ambient temperature  | [°C] | -25...90 |
| Protection           |      | IP 67    |

| Mechanical data       |      |                      |
|-----------------------|------|----------------------|
| Dimensions            | [mm] | 15 x 15 x 43         |
| Materials             |      | TPU                  |
| Moulded-body material |      | TPU                  |
| Material nut          |      | brass, nickel-plated |

| Remarks       |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |

| Electrical connection                                   |  |  |
|---------------------------------------------------------|--|--|
| Cable: 10 m, PVC, orange; 5 x 0.34 mm² (42 x Ø 0.1 mm ) |  |  |

| Electrical connection - socket                                                            |  |  |
|-------------------------------------------------------------------------------------------|--|--|
| Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated |  |  |

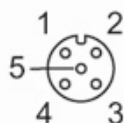


# E40051



## Connecting cable with socket

ADOGH050MSS0010E05

### Connection

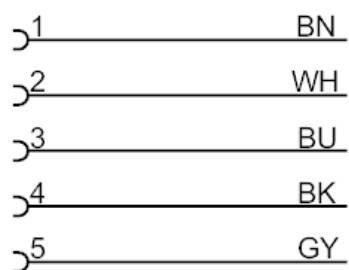

|      |                |
|------|----------------|
|      | Core colours : |
| BK = | black          |
| BN = | brown          |
| BU = | blue           |
| GY = | grey           |
| WH = | white          |