


Connecting cable with socket

ADOAH050MSN0002A05

Article no longer available - archive entry

Alternative articles: ENC10A

When selecting an alternative article and accessories please note that technical data may differ!

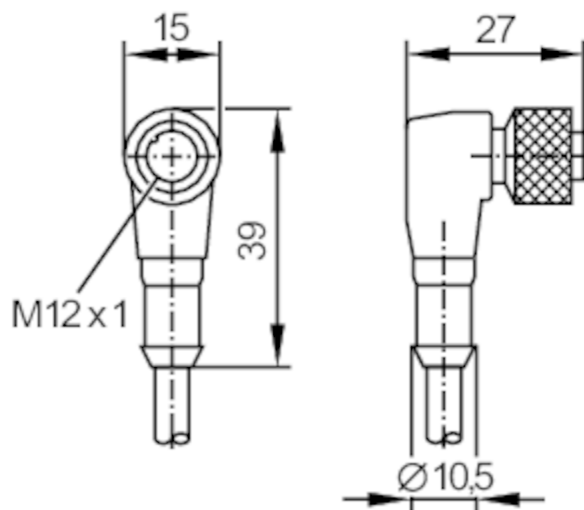

Application

Application	Ex zone 1
-------------	-----------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Safety classification

Max. internal capacitance	[nF]	0.152
---------------------------	------	-------

Max. internal inductance	[µH]	1.2
--------------------------	------	-----

Mechanical data

Dimensions	[mm]	27 x 15 x 39
------------	------	--------------

Materials	TPU
-----------	-----

Moulded-body material	TPU
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Remarks

Remarks	When using sockets in hazardous areas (ATEX) there are special requirements regarding wiring.
	The requirements of the applicable installation regulations must be absolutely adhered to by the user on his own responsibility.

Pack quantity	1 pcs.
---------------	--------

E40075



Connecting cable with socket


ADOAH050MSN0002A05

Electrical connection

Cable: 2 m, PUR / PVC, blue, Ø 6 mm; 5 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

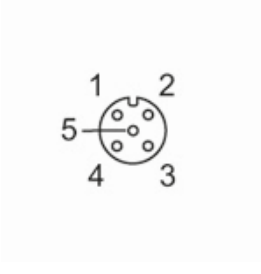

Connection

1	BN
2	WH
3	BU
4	BK
5	GY

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white