




T-piece with progressive ring fitting

T-PIECE QL18-18-18/VA

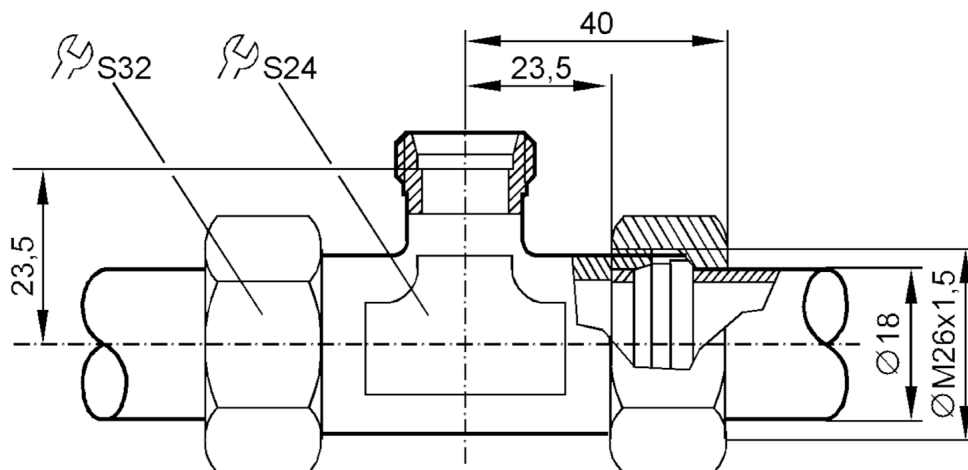

| Application | |
|------------------------------|---|
| Design | for sensors and adapters with process connection M26x1,5 |
| Application | for industrial applications |
| Media | liquids and gases |
| Pressure rating [bar] | 315 |
| Tests / approvals | |
| Pressure Equipment Directive | A possible classification to PED depends on the application and has to be carried out by the user / operator. |
| Safety instructions | The compatibility between medium and product material has to be checked in all applications. |
| Mechanical data | |
| Weight [g] | 292.7 |
| Type of mounting | Recommendation: precision steel pipes 18 x 1,5 DIN 2391/ISO 3304 |
| Materials | stainless steel (1.4571/316Ti) |
| Sensor connection | M26 x 1,5 |
| Process connection | Ø 18 mm |
| Аксессуары | |
| Accessories (optional) | Adapter: 1 x M18 x 1,5, for direct connection of flow sensors, E40104 |
| Remarks | |
| Remarks | Use a lubricating paste which is suitable and approved for the application |
| | Observe the notes on the installation of progressive ring fittings |
| Pack quantity | 1 pcs. |