


E40211



Teach button for flow sensors

SC TEACH BUTTON PS

Article no longer available - archive entry

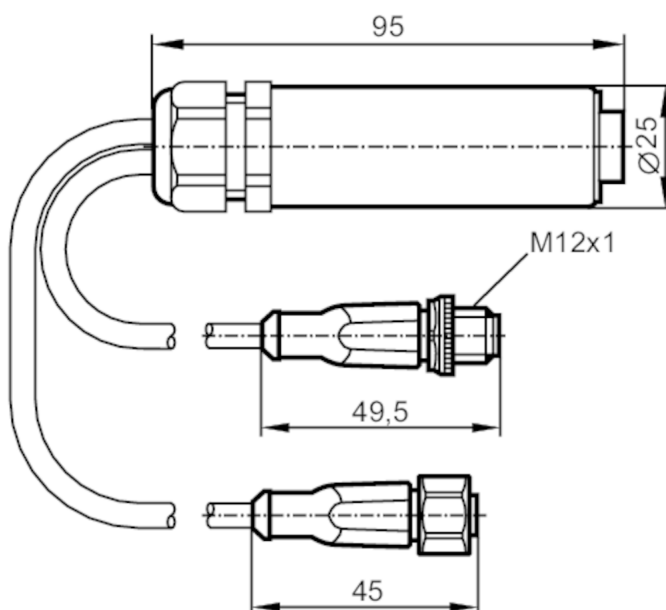

Application		
Design		for p-switching flow sensors SC
Electrical data		
Frequency AC	[Hz]	47...63
Operating voltage tolerance	[%]	15
Operating voltage	[V]	< 24 AC/DC; (to SELV/PELV)
Operating conditions		
Protection		IP 40
Mechanical data		
Weight	[g]	233
Materials		stainless steel (1.4305 / 303); PA; PMMA
Remarks		
Notes		phase-out article
Pack quantity		1 pcs.

E40211




Teach button for flow sensors

SC TEACH BUTTON PS

Electrical connection

Cable: 0.9 m, PUR

Connection

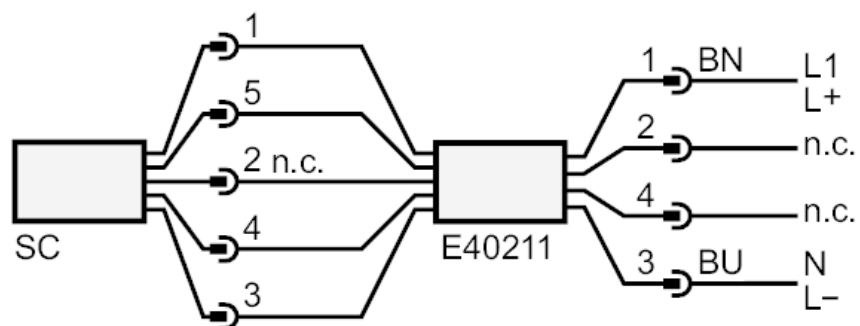

n.c. = not used
Core colours :
BN = brown
BU = blue