


Clamp fitting for process sensors

MOUNTING ADAPTER G1

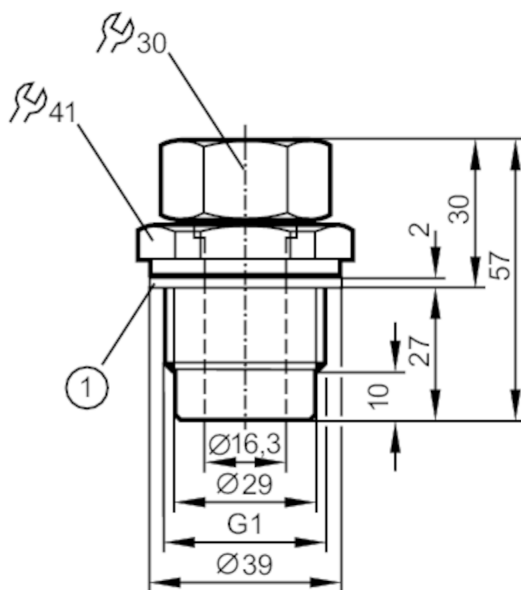

1 sealings

Application

Design for capacitive level sensors LK, LI, LT, LL

Installation Clamp fitting

Pressure rating [bar] 0.5

Operating conditions

Ambient temperature [°C] 0...80

Mechanical data

Weight [g] 335

Dimensions [mm] Ø 39 / L = 57

Materials flange: stainless steel; Lock nut: stainless steel;
spacer: brass; clamping ring: FKM; Sealing: Tesnit

Tightening torque [Nm] 6...9

Sensor connection Ø 16 mm

Process connection threaded connection G 1 external thread

Remarks

Pack quantity 1 pcs.