


E43005



Flange plate for level sensors

FLANGE PLATE 100-125 D16

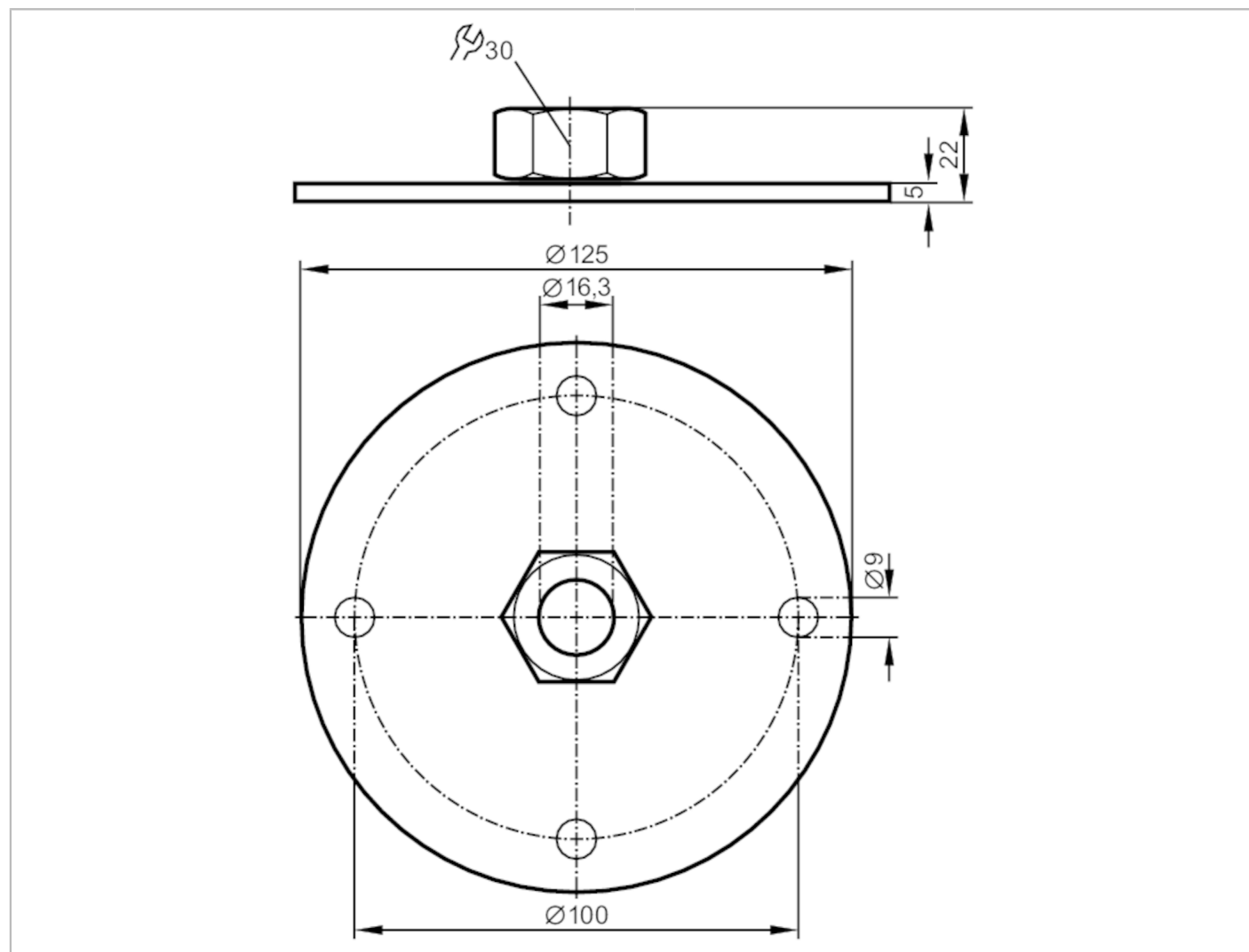

Application

Design	for capacitive level sensors LK, LI, LT, LL
Pressure rating [bar]	0.5

Operating conditions

Ambient temperature [°C]	0...80
--------------------------	--------

Mechanical data

Weight [g]	252
Materials	flange: aluminium anodised; Lock nut: stainless steel; spacer: brass; clamping ring: FKM
Tightening torque [Nm]	6...9
Sensor connection	clamp adapter Ø 16 mm
Process connection	flange

Remarks

Pack quantity	1 pcs.
---------------	--------