


E43019



Clamp fitting for process sensors

FITTING LI G3/4/D16

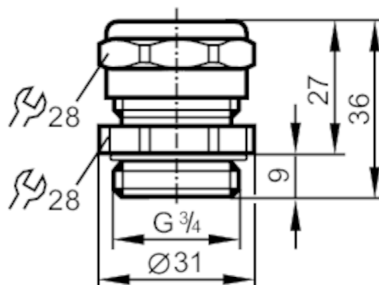

Application

Design	for capacitive level sensors LI
Installation	Clamp fitting
Pressure rating [bar]	0.5

Operating conditions

Ambient temperature [°C]	0...60
--------------------------	--------

Mechanical data

Weight [g]	67.8
Dimensions [mm]	Ø 31 / L = 36
Materials	brass nickel-plated; TPE; Sealing: FKM
Tightening torque [Nm]	10
Sensor connection	Ø 16 mm
Process connection	threaded connection G 3/4 external thread

Remarks

Pack quantity	1 pcs.
---------------	--------