




Coaxial pipe for level sensors

LR COAX TUBE NPT L700

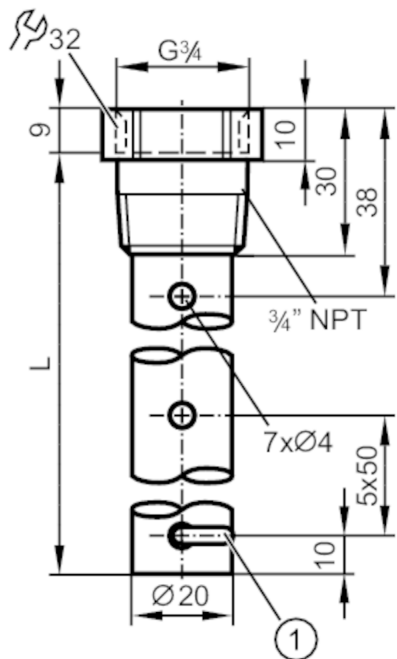

1 fixing bracket for centring piece

CRN

| Application                              |        |  |
|--|--------|--|
| Design                                   |        | for level sensors LR   |
| Medium temperature                       | [°C]   | -40...200  |
| Pressure rating                          | [bar]  | 16   |
| Vacuum resistance                        | [mbar] | -1000  |
| MAWP (for applications according to CRN) | [bar]  | 16   |
| Mechanical data                          |        |  |
| Weight                                   | [g]    | 440  |
| Materials                                |        | Coaxial pipe: stainless steel (1.4301 / 304); Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (1.4310 / 301) |
| Sensor connection                        |        | threaded connection G 3/4 internal thread  |
| Process connection                       |        | threaded connection 3/4" NPT external thread   |
| Length L                                 | [mm]   | 700  |
| Remarks                                  |        |  |
| Pack quantity                            |        | 1 pcs.   |