




Coaxial pipe for level sensors

LR COAX TUBE NPT L1200

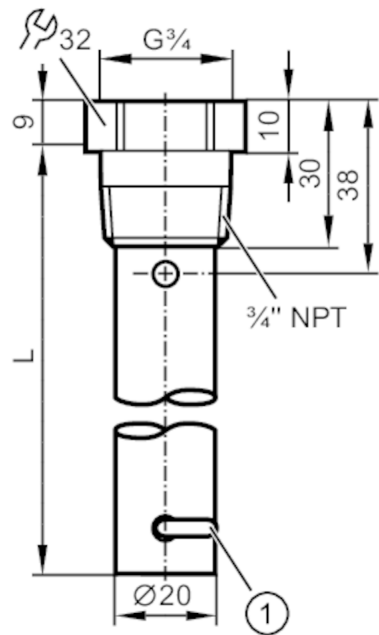

1      fixing bracket for centring piece

Application		
Design		for level sensors LR
Medium temperature	[°C]	-40...200
Pressure rating	[bar]	16
Vacuum resistance	[mbar]	-1000
Mechanical data		
Weight	[g]	645
Materials		Coaxial pipe: stainless steel (1.4301 / 304); Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (1.4310 / 301)
Sensor connection		threaded connection G 3/4 internal thread
Process connection		threaded connection 3/4" NPT external thread
Length L	[mm]	1200
Remarks		
Pack quantity		1 pcs.