


Screw coupling with cover plate

SCREW COUPLING WITH COVER PLATE 0,18MM

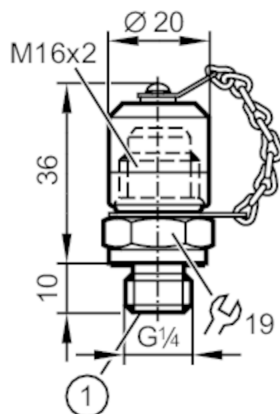

1: flow regulator 0.18 mm

Application

| | | |
|-----------------|-------|-----|
| Pressure rating | [bar] | 630 |
|-----------------|-------|-----|

Operating conditions

| | | |
|---------------------|------|----------|
| Ambient temperature | [°C] | -10...60 |
|---------------------|------|----------|

Tests / approvals

| | |
|------------------------------|---|
| Pressure Equipment Directive | A possible classification to PED depends on the application and has to be carried out by the user / operator. |
|------------------------------|---|

| | |
|---------------------|--|
| Safety instructions | The compatibility between medium and product material has to be checked in all applications. |
|---------------------|--|

Mechanical data

| | | |
|--------------------|---|------|
| Weight | [g] | 76.3 |
| Materials | socket housing: steel (1.0718); surface characteristics: zinc / nickel grey; Sealing: NBR | |
| Sensor connection | G 1/4 | |
| Process connection | M16 x 2 Minimes | |

Remarks

| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|