




Screw coupling with cover plate

SCREW COUPLING WITH COVER PLATE 0,3MM

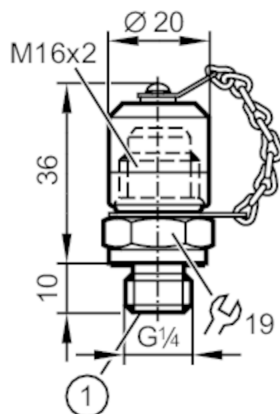

1: flow regulator 0.3 mm

Application

Pressure rating	[bar]	630
-----------------	-------	-----

Operating conditions

Ambient temperature	[°C]	-10...60
---------------------	------	----------

Tests / approvals

Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
------------------------------	---

Safety instructions	The compatibility between medium and product material has to be checked in all applications.
---------------------	--

Mechanical data

Weight	[g]	76.2
--------	-----	------

Materials	socket housing: steel (1.0718); surface characteristics: zinc / nickel grey; Sealing: NBR
-----------	---

Sensor connection	G 1/4
-------------------	-------

Process connection	M16 x 2 Minimes
--------------------	-----------------

Remarks

Pack quantity	1 pcs.
---------------	--------