




Coaxial pipe for level sensors

LR COAX TUBE G3/4 L800

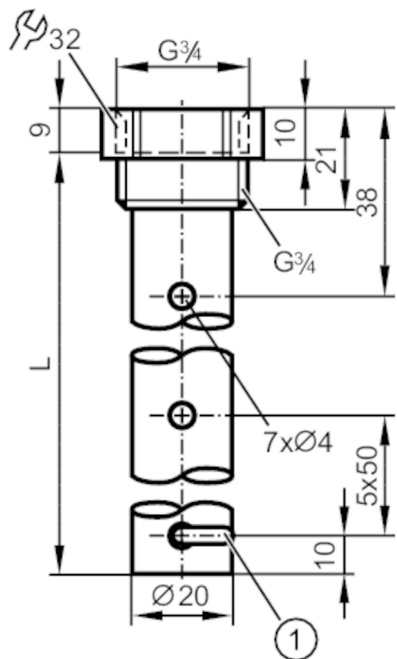

1 fixing bracket for centring piece

Application

Design	for level sensors LR
Medium temperature [°C]	-40...200
Pressure rating [bar]	16
Vacuum resistance [mbar]	-1000

Mechanical data

Weight [g]	475
Materials	Coaxial pipe: stainless steel (1.4301 / 304); Sealing: NBR reinforced fibre; fixing bracket: stainless steel (1.4310 / 301); Centring piece: PPS reinforced fibre
Sensor connection	threaded connection G 3/4 internal thread
Process connection	threaded connection G 3/4 external thread
Length L [mm]	800

Аксессуары

Items supplied	Sealing: 1
Accessories (optional)	Centring piece for coaxial pipes: 1, E43222

Remarks

Remarks	When used under DNV GL conditions mounting of an additional centring piece is required
Pack quantity	1 pcs.