




Coaxial pipe for level sensors

LR COAX TUBE G3/4 L210

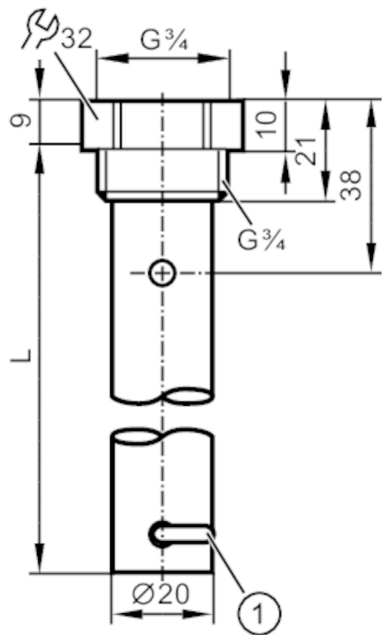

1 fixing bracket for centring piece

CRN

Application		
Design		for level sensors LR
Medium temperature	[°C]	-40...200
Pressure rating	[bar]	16
Vacuum resistance	[mbar]	-1000
MAWP (for applications according to CRN)	[bar]	16
Mechanical data		
Weight	[g]	164.5
Materials	Coaxial pipe: stainless steel (1.4301 / 304); Sealing: NBR reinforced fibre; fixing bracket: stainless steel (1.4310 / 301); Centring piece: PPS reinforced fibre	
Sensor connection	threaded connection G 3/4 internal thread	
Process connection	threaded connection G 3/4 external thread	
Length L	[mm]	210
Аксессуары		
Items supplied	Sealing: 1	
Remarks		
Pack quantity	1 pcs.	