


E60122




Wirable socket

SDOGK120MKRFGSG

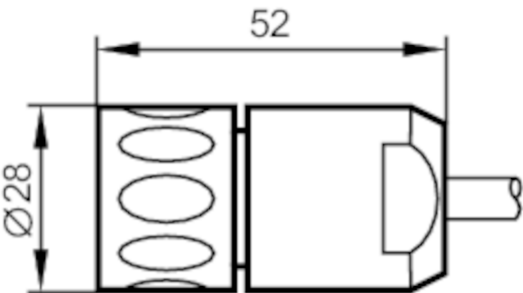

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	43
Dimensions	[mm]	28 x 28 x 52
Materials		brass in plastic sheath; PA 6.6 black
Moulded-body material		brass / PA 6.6, in plastic sheath
Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
Remarks		
Pack quantity		1 pcs.
Electrical connection		
soldering: ...1 mm ²		
Electrical connection - socket		

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath
Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

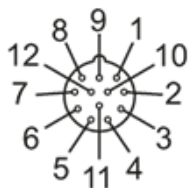

E60122

Wirable socket

SDOGK120MKRFKSG



Connection

