


E60136



Wirable socket


SDOGK120MKRFGSG

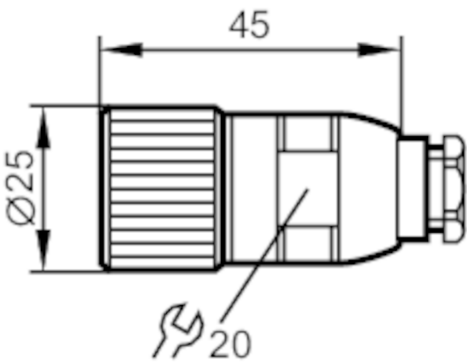

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...125
Protection		IP 67
Mechanical data		
Weight	[g]	79
Dimensions	[mm]	25 x 25 x 45
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
soldering: ...1 mm ² ; Cable sheath: Ø 4.5...6 mm	

Electrical connection - socket	
Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated	

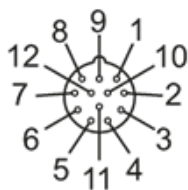

E60136

Wirable socket

SDOGK120MKRFKSG



Connection

