


E60146



Wirable socket

SDOGK210MKRFKSG

Article no longer available - archive entry

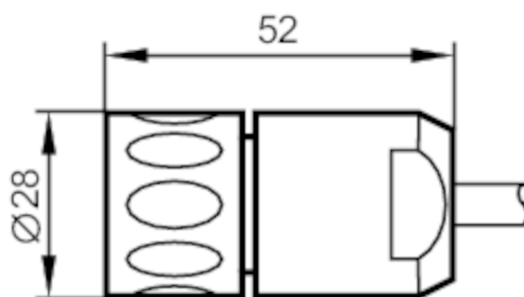

Electrical data

Operating voltage	[V]	4.5...30 DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-40...125
---------------------	------	-----------

Protection		IP 67
------------	--	-------

Mechanical data

Weight	[g]	68.8
--------	-----	------

Dimensions	[mm]	28 x 28 x 52
------------	------	--------------

Materials		brass in plastic sheath; PA 6.6 black
-----------	--	---------------------------------------

Moulded-body material		brass / PA 6.6, in plastic sheath
-----------------------	--	-----------------------------------

Material nut		brass, in plastic sheath / PA 6.6, in plastic sheath
--------------	--	--

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E60146



Wirable socket

SDOGK210MKRFKSG


Electrical connection

soldering/crimping connection: ...0.5 mm²

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

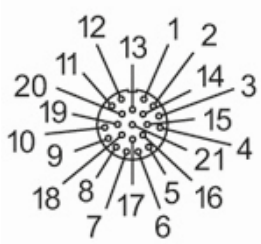

Connection

- 1 _____
- 2 _____
- 3 _____
- 4 _____
- 5 _____
- 6 _____
- 7 _____
- 8 _____
- 9 _____
- 10 _____
- 11 _____
- 12 _____
- 13 _____
- 14 _____
- 15 _____
- 16 _____
- 17 _____
- 18 _____
- 19 _____
- 20 _____
- 21 _____