


E60174



Wirable socket

SDOGJ120MSLFBPG

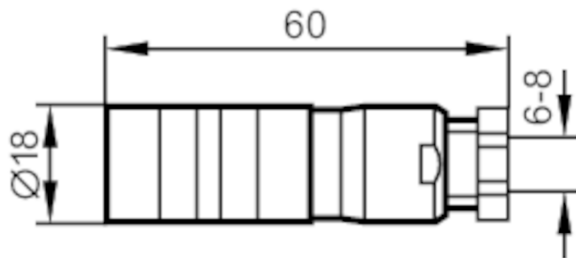

Electrical data		
Operating voltage	[V]	4.5...30 DC
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Weight	[g]	55.3
Dimensions	[mm]	18 x 18 x 60
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E60174



Wirable socket

SDOGJ120MSLFPKG

Electrical connection

soldering: ...0.25 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

Connector: 1 x M18, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated



Connection

