


E70450




Connection cable

Edge-Gateway/Power cable M12

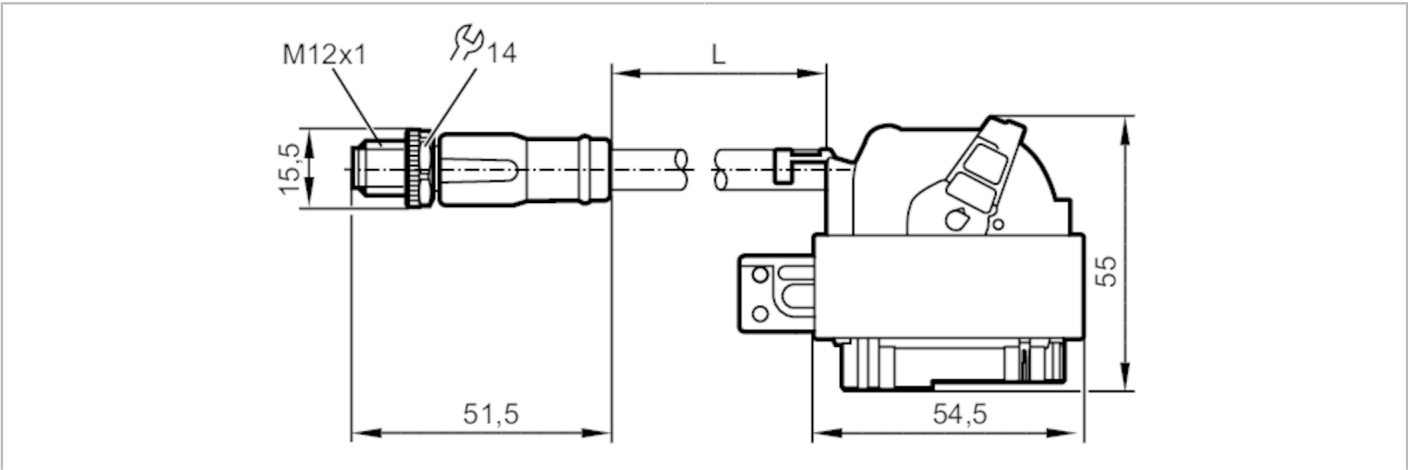

Application	
Application	voltage supply for edgeGateway
Electrical data	
Operating voltage	[V] 8...32 DC
Operating conditions	
Storage temperature	[°C] -40...105
Protection	IP 65
Mechanical data	
Weight	[g] 111.5
Materials	PBT-GF20
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 0.6 m, PVC; FLRY-B	
Connection	

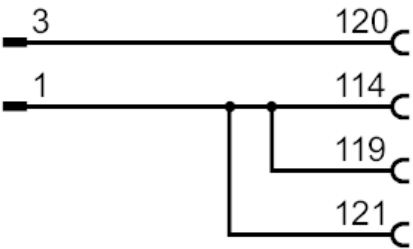

E70450



Connection cable

Edge-Gateway/Power cable M12

Electrical connection - plug



1	L+
2	N.C.
3	L-
4	N.C.