




AS-Interface flat cable insulation displacement connector

FC Splitter AS-i 0.6 m M12 UL

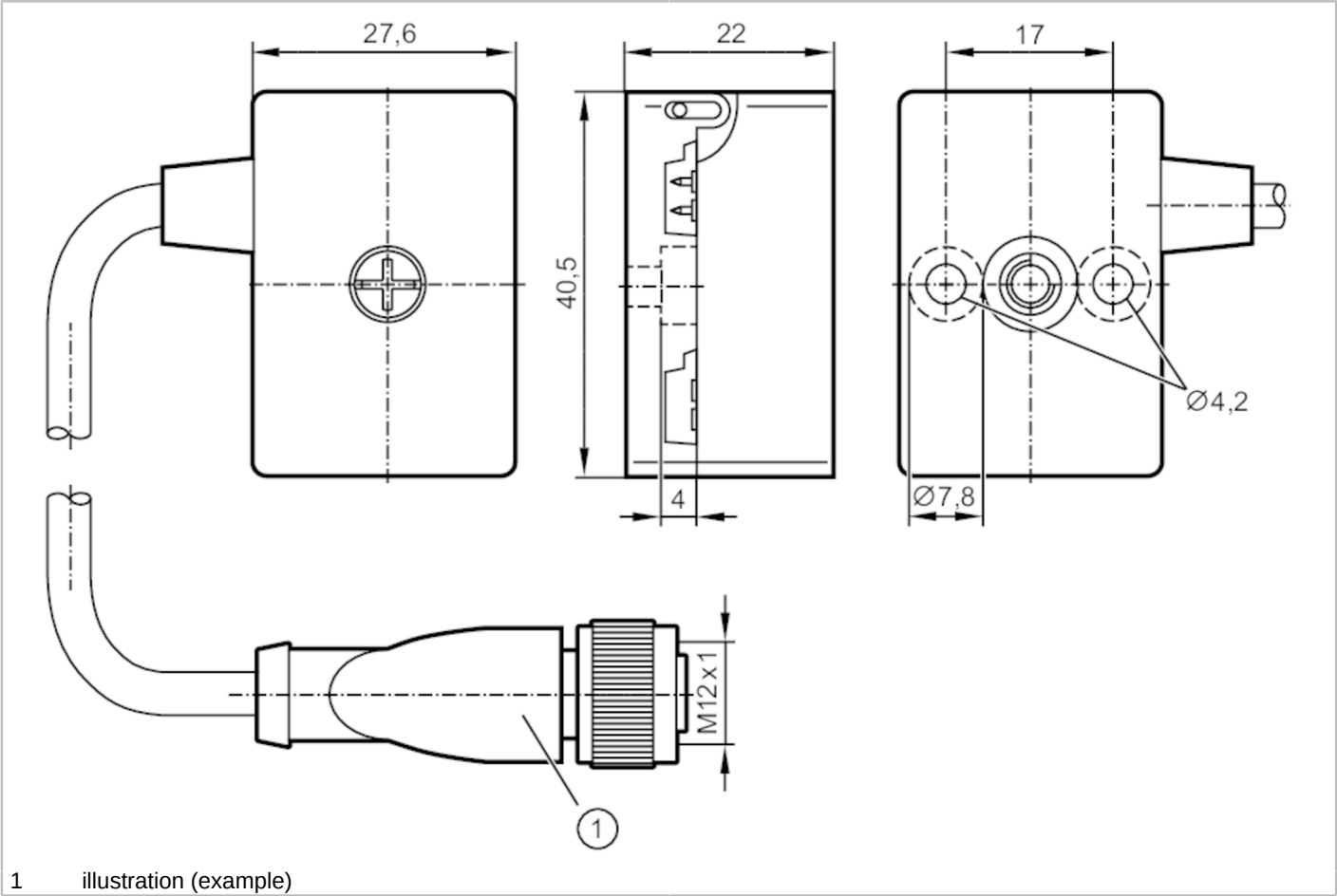

Application		
Application		distribution of the AS-i voltage to M12 socket
Electrical data		
Protection class		III
Max. current load per module/slot	[A]	4
Outputs		
Electrical design		AS-i
Operating conditions		
Ambient temperature	[°C]	-25...75
Protection		IP 67
Mechanical data		
Weight	[g]	83.1
Materials		housing: PBT / PC
Tightening torque	[Nm]	1.65
Аксессуары		
Accessories (optional)		flat cable end seal:, E70413
		heat-shrink cap:, E70113



AS-Interface flat cable insulation displacement
connector


FC Splitter AS-i 0.6 m M12 UL

Remarks	
Remarks	The flat cable must not end in the splitter. Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.


Electrical connection

Cable: 0.6 m, PUR, Ø 4.3 mm; 2 x 0.34 mm²

Connector: M12; coding: A; Moulded body: PUR

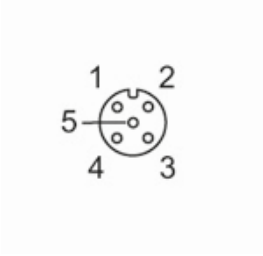

Connection

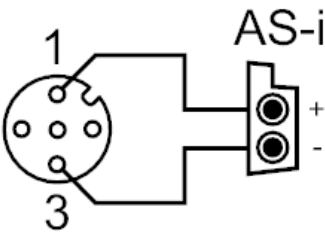

1	AS-i +
3	AS-i -