




AS-Interface flat cable insulation displacement
connector

FC Splitter AS-i / AUX M12 UL

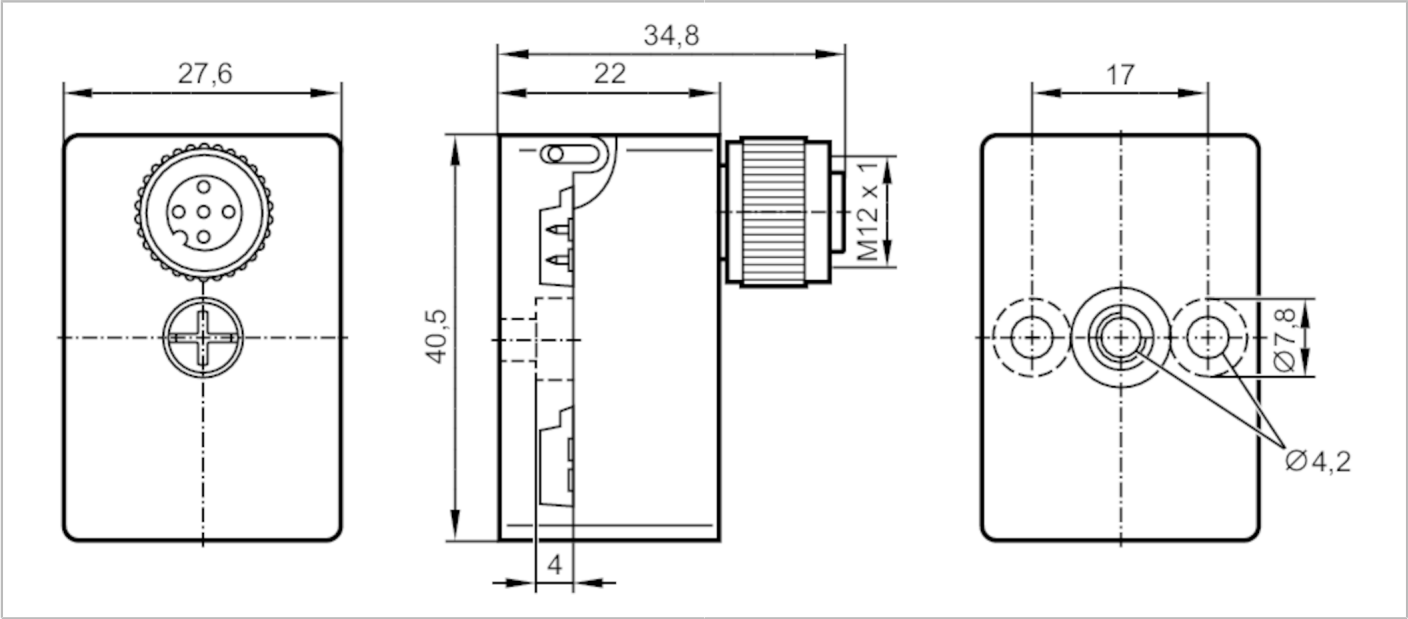

Electrical data	
Protection class	III
Max. current load per module/slot [A]	4
Outputs	
Electrical design	AS-i
Operating conditions	
Ambient temperature [°C]	-25...75
Protection	IP 67
Mechanical data	
Weight [g]	60.5
Materials	housing: PBT / PC; screw: stainless steel (1.4305 / 303)
Tightening torque [Nm]	< 1.65
Аксессуары	
Accessories (optional)	flat cable end seal:, E70413
	heat-shrink cap:, E70113
Remarks	
Remarks	The flat cable should not end in the splitter.
	Use a flat cable seal or heat-shrink cap for sealing.
Pack quantity	1 pcs.




AS-Interface flat cable insulation displacement
connector


FC Splitter AS-i / AUX M12 UL

Electrical connection

Connector: M12; coding: A; Moulded body: PUR

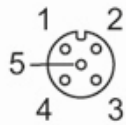

Connection

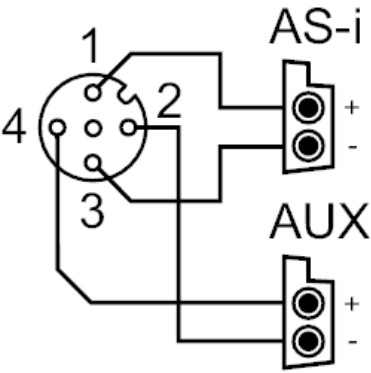

1	AS-i +
2	AUX -
3	AS-i -
4	AUX +