




Connection cable


VSTA030MSS0002A02VDAB031--S

Article no longer available - archive entry

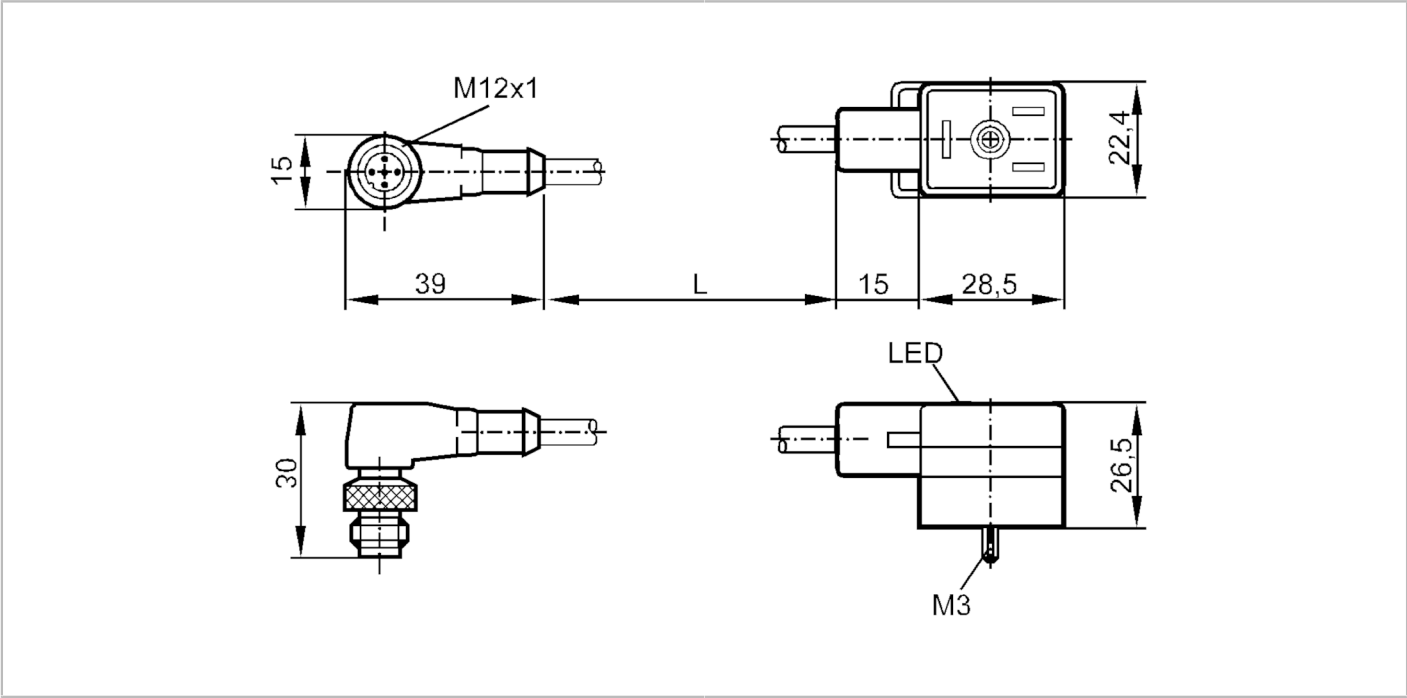

| Electrical data              |      |                      |
|------------------------------|------|----------------------|
| Operating voltage            | [V]  | 10...30 DC           |
| Operating conditions         |      |                      |
| Ambient temperature          | [°C] | -25...90             |
| Protection                   |      | IP 67                |
| Mechanical data              |      |                      |
| Dimensions                   | [mm] | 15 x 30 x 39         |
| Materials                    |      | PUR                  |
| Moulded-body material        |      | PUR                  |
| Material nut                 |      | brass, nickel-plated |
| Аксессуары                   |      |                      |
| Items supplied               |      | screw                |
|                              |      | panel for labelling  |
| Remarks                      |      |                      |
| Pack quantity                |      | 1 pcs.               |
| Electrical connection - plug |      |                      |

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

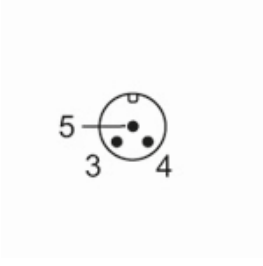

# E70005




## Connection cable

VSTAH030MSS0002A02VDAB031--S

### Electrical connection

Cable: 2 m, PUR / PVC; 2 x

### Connection

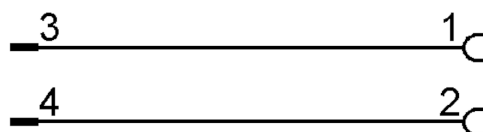

### Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

