




Connection cable

VVDAB031--S0015A03STAH030MSS

Article no longer available - archive entry

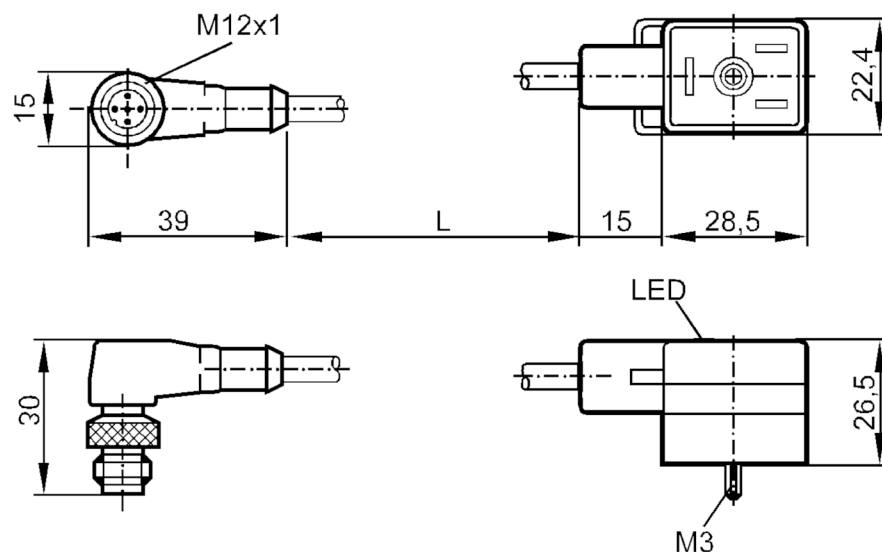

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Dimensions	[mm]	15 x 30 x 39
------------	------	--------------

Materials	PUR
-----------	-----

Moulded-body material	PUR
-----------------------	-----

Material nut	brass, nickel-plated
--------------	----------------------

Аксессуары


Items supplied	screw panel for labelling
----------------	------------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

 Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



E70006




Connection cable

VVDAB031--S0015A03STAH030MSS

Electrical connection

Cable: 15 m, PUR / PVC; 2 x

Connection

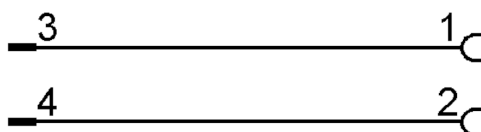

Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

