

E70014




Connection cable

VDOGF030MSS00,3A03STGH030MSS

Article no longer available - archive entry


Alternative articles: EVC215
When selecting an alternative article and accessories please note that technical data may differ!

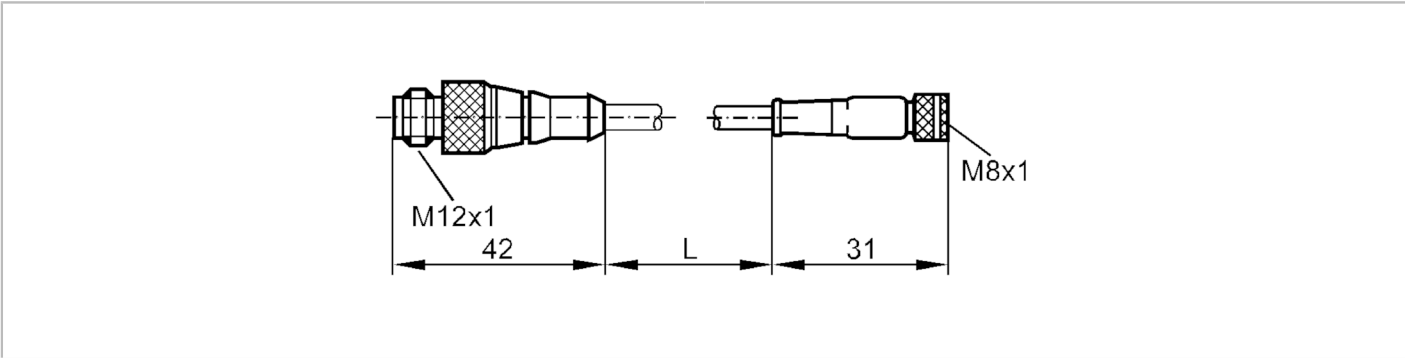

Electrical data		
Operating voltage	[V]	10...30 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

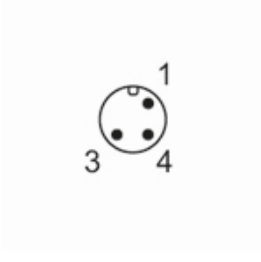

E70014




Connection cable

VDOGF030MSS00,3A03STGH030MSS

Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.34 mm²

Connection

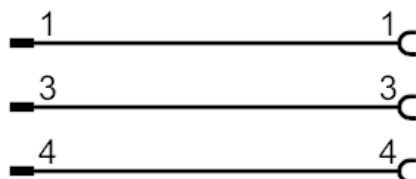

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

