

E70055




Connection cable

VDOAH040MSS01,5A04STAH040MSS

Article no longer available - archive entry

Alternative articles: EVC167  
When selecting an alternative article and accessories please note that technical data may differ!

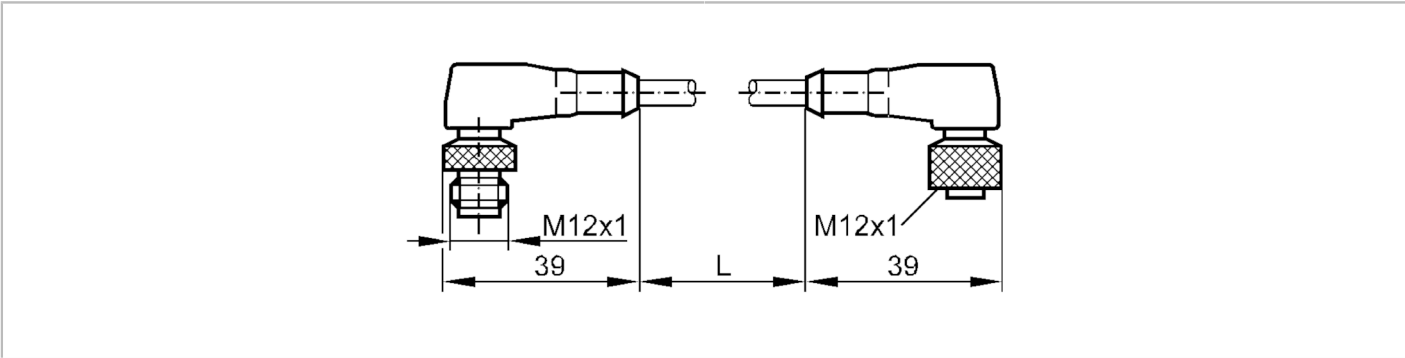

Electrical data

|                   |     |            |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
|-------------------|-----|------------|

Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 67    |

Mechanical data


|                       |                      |
|-----------------------|----------------------|
| Materials             | TPU                  |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

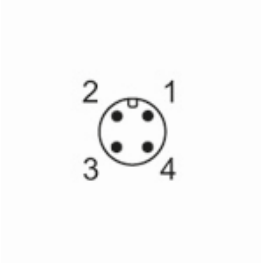

# E70055



## Connection cable

VDOAH040MSS01,5A04STAH040MSS

### Electrical connection

Cable: 1.5 m, PUR / PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

