




AS-Interface flat cable insulation displacement connector

FLAT CABLE CONNECTOR M12

Alternative articles: E75005

When selecting an alternative article and accessories please note that technical data may differ!

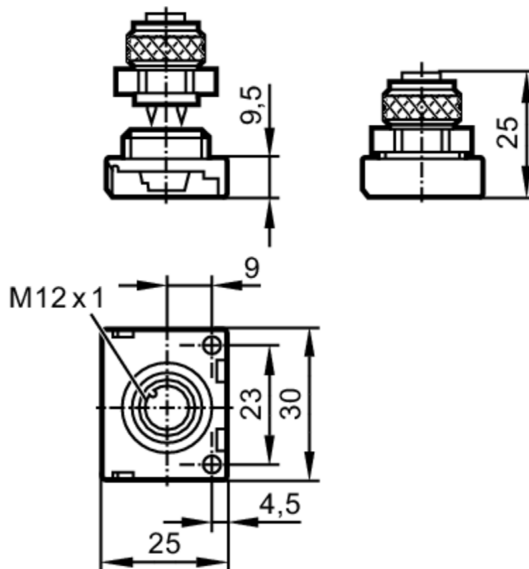

Application

Design

AS-i

Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current load total	[A]	2

Operating conditions

Ambient temperature	[°C]	-25...75
Protection		IP 67

Mechanical data

Weight	[g]	17.9
Materials		PA
Moulded-body material		PA

Remarks

Remarks	installation instructions First separate the fixture (orange) from the insulation displacement connector. Insert the cable in the fixture and close it again. Screw the fixture back on the insulation displacement connector.
Pack quantity	1 pcs.

Electrical connection

	when connected to yellow AS-i flat cable
1	AS-i +
3	AS-i -
	when connected to black flat cable
1	+24V DC
3	0V

E70096



AS-Interface flat cable insulation displacement connector

FLAT CABLE CONNECTOR M12

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: PA

