

E70100




Wirable socket

SDOGL070PLSFKPG

Article no longer available - archive entry

Alternative articles: E70142

When selecting an alternative article and accessories please note that technical data may differ!

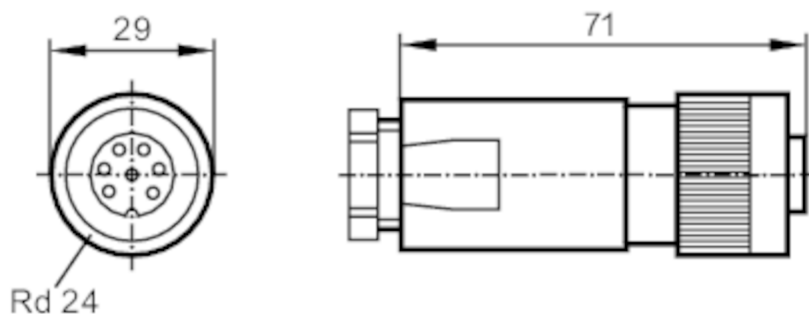

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	10

Operating conditions

Ambient temperature	[°C]	-40...100
Protection		IP 67

Mechanical data

Dimensions	[mm]	29 x 29 x 71
Materials		PBT
Moulded-body material		PBT
Material nut		PBT

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E70100



Wirable socket

 
SDOGL070PLSFKPG

Electrical connection

terminals: ...2.5 mm²; Cable sheath: Ø 10...12 mm

Electrical connection - socket

Connector: 1 x Rd24, straight; coding: A; Moulded body: PBT; Locking: PBT



Connection

