

E70103




Jumper cable with valve plug

VVDAB031--S00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11421
When selecting an alternative article and accessories please note that technical data may differ!

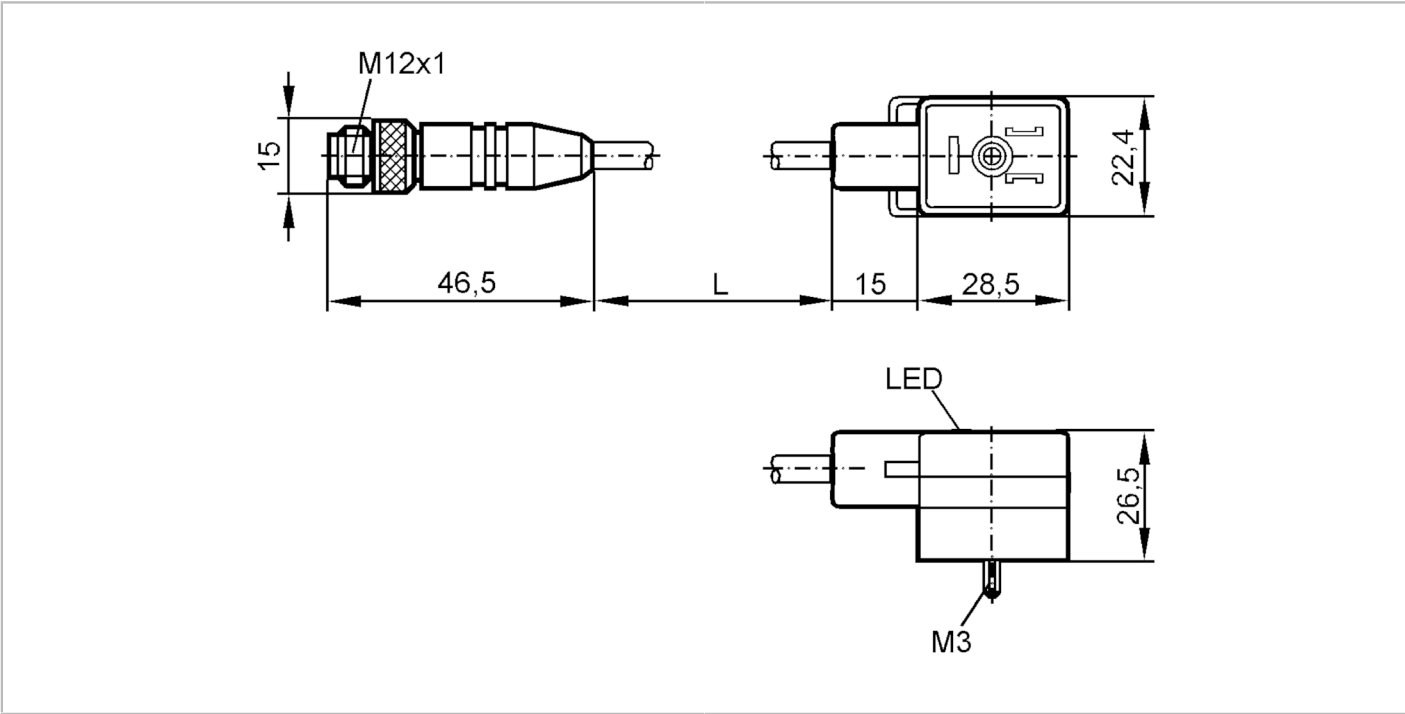

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overtoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
Аксессуары		
Items supplied		screw
		panel for labelling
Remarks		
Pack quantity		1 pcs.

E70103



Jumper cable with valve plug

VVDAB031--S00,3A03STGH030MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type B DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

