




Connection cable

VDOGH040MSS00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: EVC040
When selecting an alternative article and accessories please note that technical data may differ!

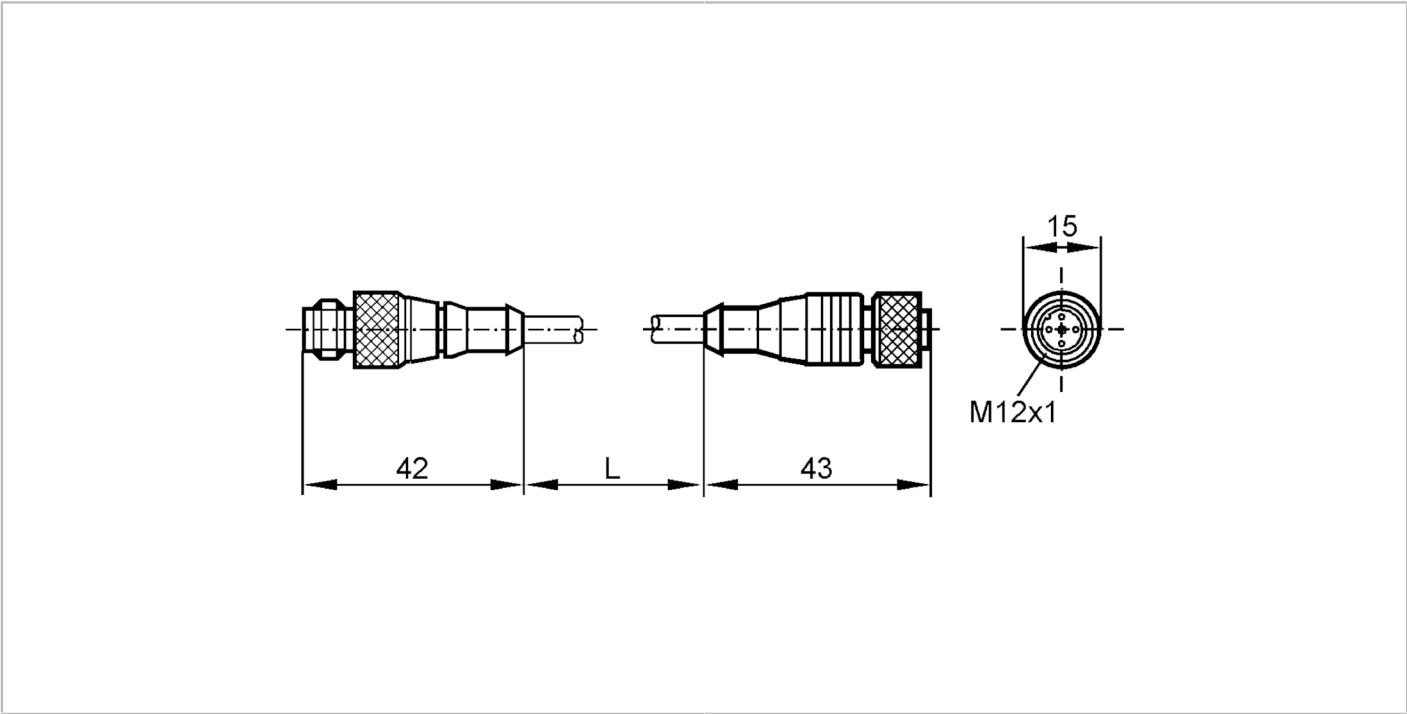

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data


Dimensions	[mm]	15 x 15 x 42
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

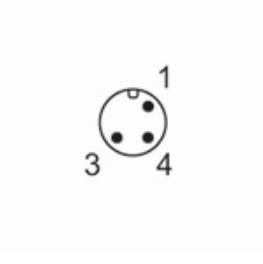

E70114



Connection cable

VDOGH040MSS00,3A03STGH030MSS

Electrical connection

Cable: 0.3 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

