


E70129



Jumper cable with valve plug

VDAA0401--S0002A03STAH030MSS

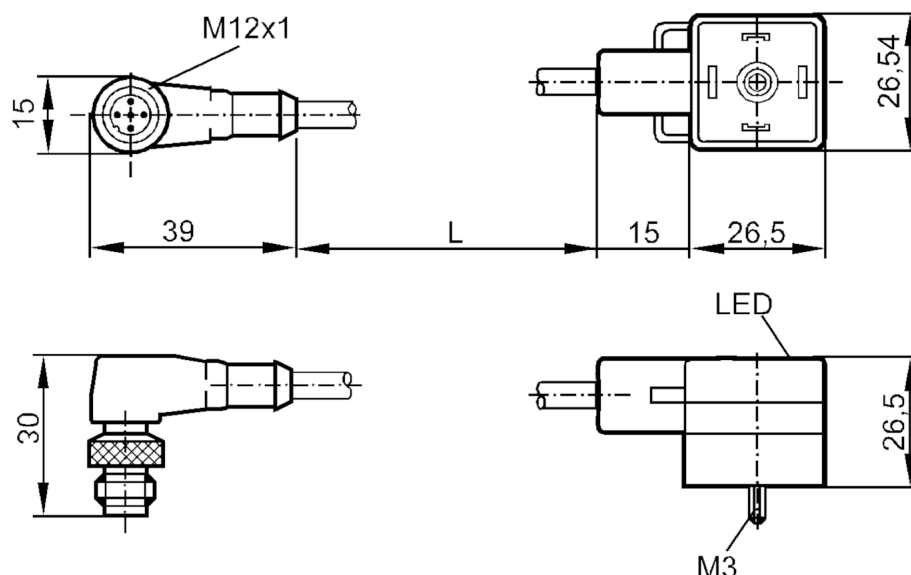

Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	138.5
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Аксессуары		
Items supplied		screw panel for labelling
Remarks		
Pack quantity		1 pcs.

E70129




Jumper cable with valve plug

VDAA0401--S0002A03STAH030MSS

Electrical connection - socket

 
Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.8 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

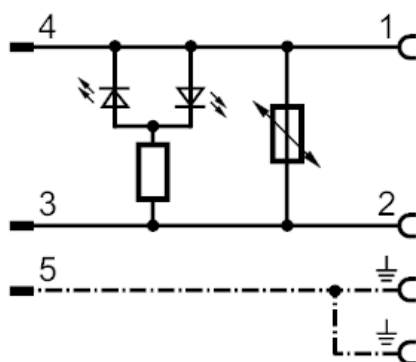

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

