

# E70134




## Wirable socket

SDOKL070PLSFKPG

Article no longer available - archive entry

Alternative articles: E70142

When selecting an alternative article and accessories please note that technical data may differ!

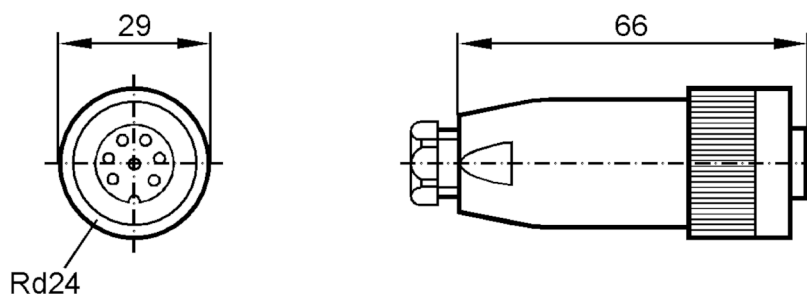

### Application

Special feature

Gold-plated contacts

### Electrical data

Operating voltage

[V]

< 250 AC / < 300 DC

### Operating conditions

Ambient temperature

[°C]

-40...100

Protection

IP 67

### Mechanical data

Dimensions

[mm]

29 x 29 x 66

Materials

PBT

Moulded-body material

PBT

Material nut

PBT

### Remarks

Pack quantity

1 pcs.

# E70134



## Wirable socket

 
SDOKL070PLSFKPG

### Electrical connection

terminals: ...2.5 mm<sup>2</sup>; Cable sheath: Ø 6...9.5 mm

### Electrical connection - socket

Connector: 1 x Rd24, straight; coding: A; Moulded body: PBT; Locking: PBT; Contacts: gold-plated



### Connection

