


E70171



Connecting cable with plug

ASTGB040PLS0002E04

Article no longer available - archive entry

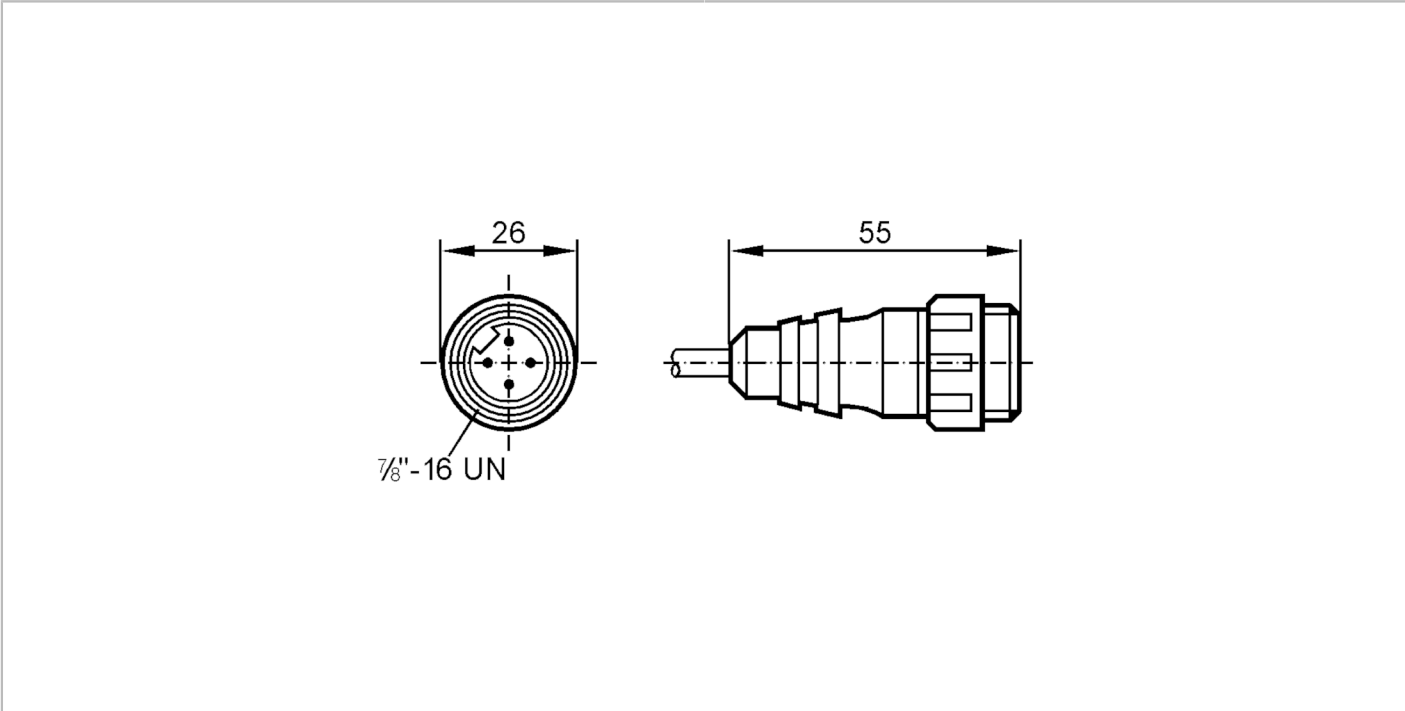

Electrical data

Operating voltage	[V]	< 250 AC / 10...55 DC
-------------------	-----	-----------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	26 x 26 x 55
Materials		TPU
Moulded-body material		TPU
Material nut		PA

Remarks


Remarks	pin 2 leading
Pack quantity	1 pcs.

Electrical connection

Cable: 2 m, PVC, orange, Ø 6.3 mm; 4 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - plug

Connector: 1 x 7/8", straight; coding: A; Moulded body: TPU; Locking: PA; Tightening torque: 0.5 Nm

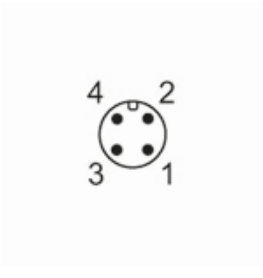

E70171



Connecting cable with plug

ASTGB040PLS0002E04

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white