


Connection cable

VDOGH040VAS0005E04STGH040VAS

Article no longer available - archive entry

Alternative articles: EVT044

When selecting an alternative article and accessories please note that technical data may differ!

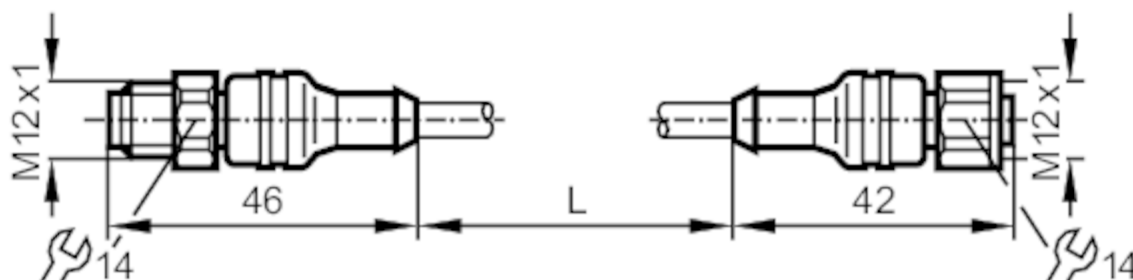

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E70185



Connection cable

VDOGH040VAS0005E04STGH040VAS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Electrical connection

Cable: 5 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

