


E70190



Adapter plug

ESTGH050ZDS00,5E05 (PG9)

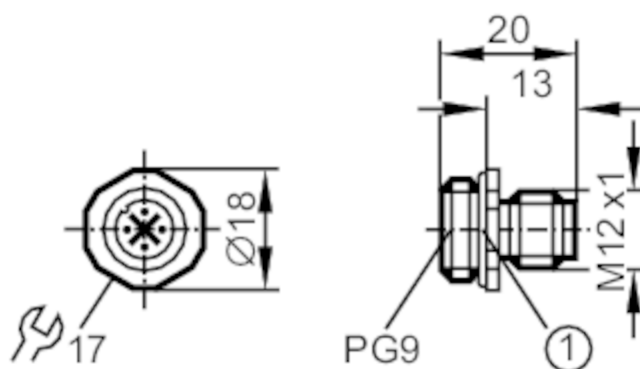

1 O-ring



Electrical data

Operating voltage	[V]	< 125 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...85
---------------------	------	----------

Protection		IP 68
------------	--	-------

Mechanical data

Weight	[g]	19.9
--------	-----	------

Dimensions	[mm]	18 x 18 x 20
------------	------	--------------

Mounting thread		PG 9
-----------------	--	------

Materials		diecast zinc
-----------	--	--------------

Moulded-body material		diecast zinc
-----------------------	--	--------------

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E70190



Adapter plug

ESTGH050ZDS00,5E05 (PG9)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm² + 1 x 0.5 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: diecast zinc



Connection

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN/YE =	green/yellow
WH =	white