




Connection cable

VDOAH030VAS0001E03STGH030VAS

Article no longer available - archive entry

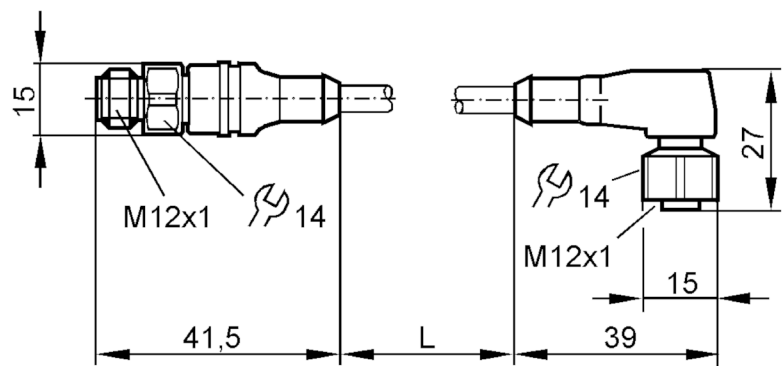

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 41.5
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L)



E70202



Connection cable

VDOAH030VAS0001E03STGH030VAS

Electrical connection

Cable: 1 m, PVC; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection



Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L)

