

E70204




Connection cable

VDOGH040VAS0001E04STGH040VAS

Article no longer available - archive entry

Alternative articles: EVT042

When selecting an alternative article and accessories please note that technical data may differ!

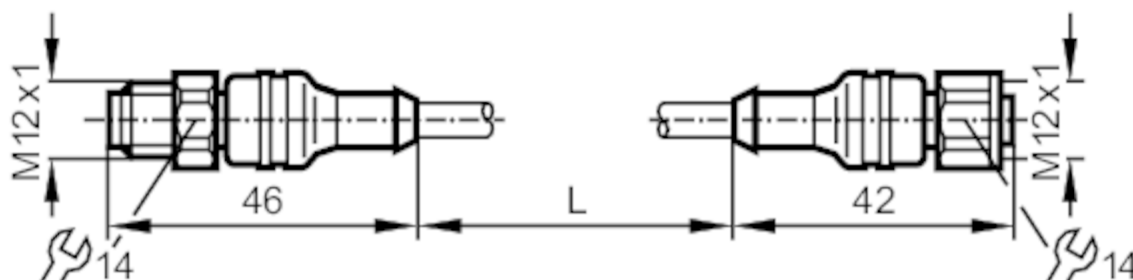

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68; IP 69K

Mechanical data

Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------



Connection cable

VDOGH040VAS0001E04STGH040VAS

Electrical connection

Cable: 1 m, PVC, Ø 5.3 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated;
Tightening torque: 0.7...0.9 Nm



Electrical connection

Connection

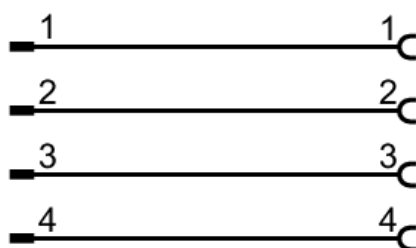

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated;
Tightening torque: 0.7...0.9 Nm

