




Jumper cable with valve plug

VVDAA042--S0005B05STGH050MSS

Article no longer available - archive entry

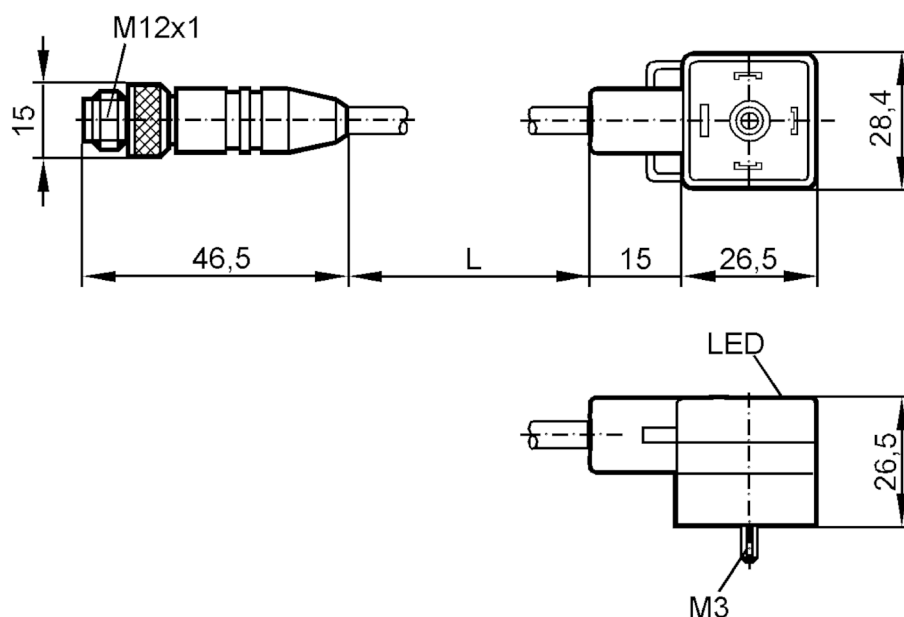

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Аксессуары

Items supplied		screw
		panel for labelling

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E70215



Jumper cable with valve plug

VVDAA042--S0005B05STGH050MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 5 m, PUR; 3 x 0.5 mm²

Connection

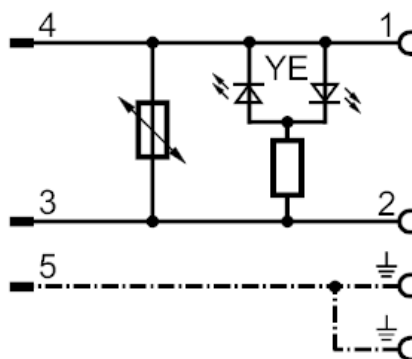

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

