




AS-Interface flat cable splitter

FCE Splitter ye/ye ProcessL

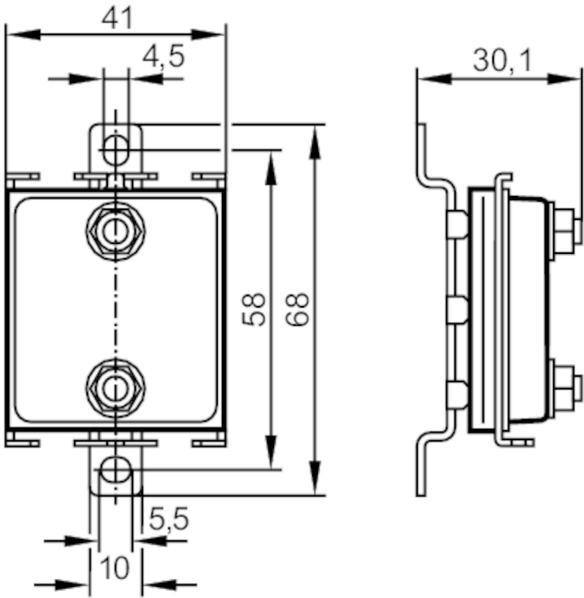

Application		
Design	AS-i / 24 V	
Application	hygienic and wet areas in the food industry	
Electrical data		
Protection class	III	
Max. current load total	[A]	8
Outputs		
Electrical design	AS-i	
Operating conditions		
Ambient temperature	[°C]	-30...80
Max. relative air humidity	[%]	80; (31 °C; linearly decreasing to 50 % (40 °C))
Max. height above sea level	[m]	2000
Protection	IP 67; IP 68; IP 69K	
Pollution degree	2	
Tests / approvals		
EMC	EN 61000-6-2	
Mechanical data		
Weight	[g]	101.5
Materials	metal parts: stainless steel (1.4404 / 316L); rubber gasket for contact pins: FPM; O-ring: EPDM	
Tightening torque	[Nm]	2.5; (lock nuts)
Аксессуары		
Accessories (optional)	Torque wrench, E70390	

E70377



AS-Interface flat cable splitter

FCE Splitter ye/ye ProcessL

Remarks	
Pack quantity	1 pcs.