


Wall passage

Wall passage standard

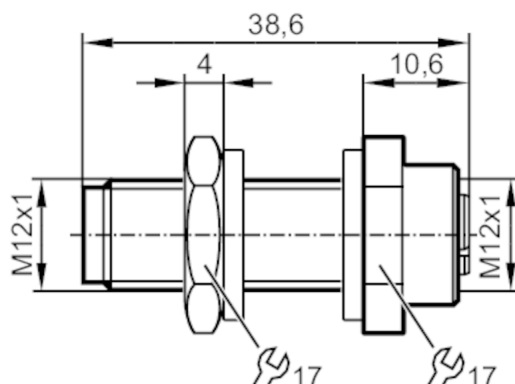

Electrical data

Operating voltage	[V]	< 60 AC/DC
Max. current load total	[A]	8; (pin 1+3: 4 A; pin 2+4: 4 A)

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 65; IP 67

Mechanical data


Weight	[g]	24.1
Materials		brass nickel-plated; Sealing: FKM
Moulded-body material		brass, nickel-plated
Tightening torque	[Nm]	1

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated

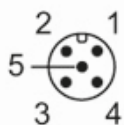


E73008



Wall passage

Wall passage standard

Connection

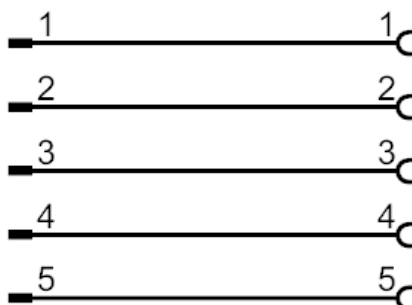

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated

