


E80353



RFID tag

ID-TAG/R30X10/04

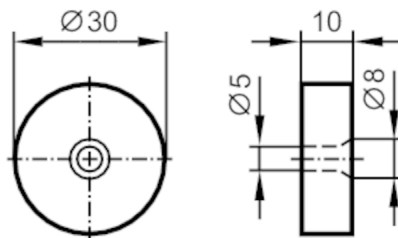

Application

Operating temperature (active)	[°C]	-25...85
Peak temperature (passive)	[°C]	100

Electrical data

Operating frequency	[MHz]	865...870
Memory size	[bit]	128
Max. read cycles		unlimited
Max. write cycles		100000

Operating conditions

Ambient temperature	[°C]	-25...85
Storage temperature	[°C]	-40...100

Mechanical data

Weight	[g]	8.75
Dimensions	[mm]	Ø 30 / L = 10
Materials		PU black

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Other data

read distance (m)

DTE80x	0.5
DTE90x	-
ANT860 / ANT960	-
ANT820 / ANT920	-