




Splitter box

ZDO4H055MSS0000-00STAK120MSS

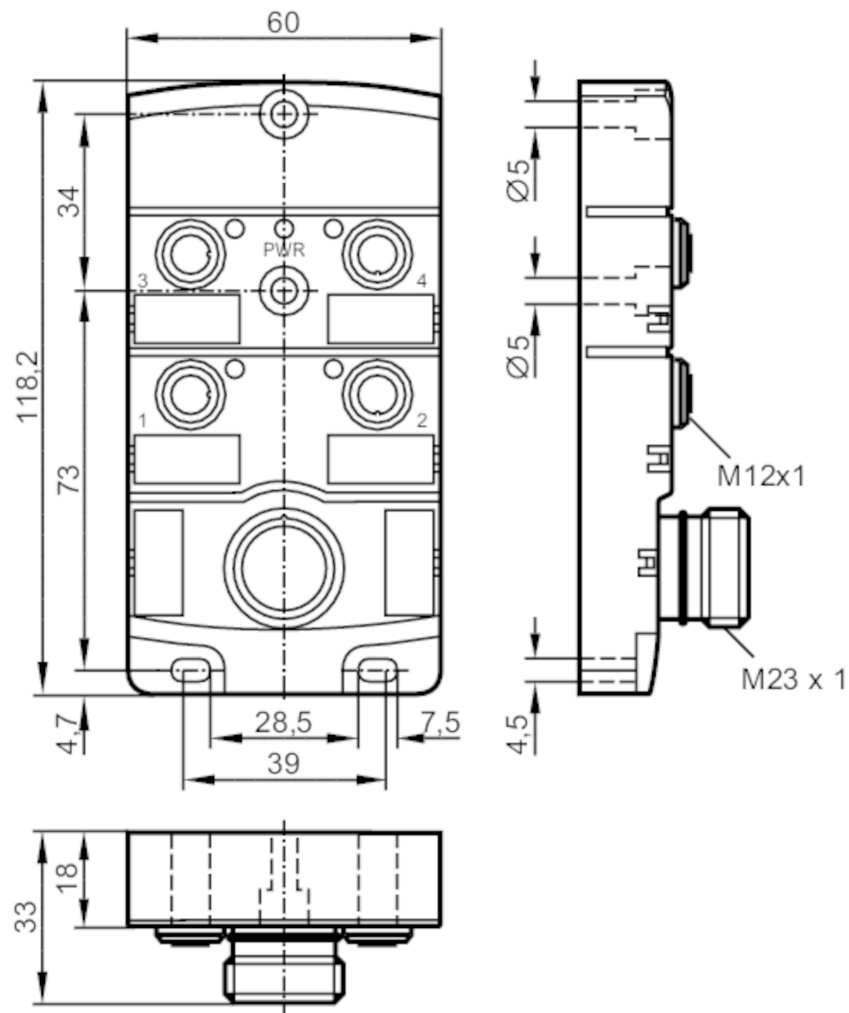


Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Outputs		
Electrical design		PNP



Splitter box

ZDO4H055MSS0000-00STAK120MSS

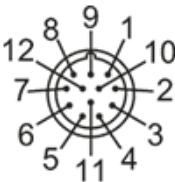
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Tests / approvals		
UL approval	Enclosure type	Type 1
Mechanical data		
Weight	[g]	224.5
Dimensions	[mm]	33 x 60 x 118.2
Materials		PA
Moulded-body material		PA
Number of ports splitter box		4
Connector type		M12
Displays / operating elements		
Display	switching status	4 x LED, yellow
	operation	1 x LED, green
Аксессуары		
Items supplied	захисні заглушки: 2	
	labels: 4	
Remarks		
Pack quantity	1 pcs.	
Electrical connection - Connection		
Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm		
		



Splitter box

ZDO4H055MSS0000-00STAK120MSS

Connection

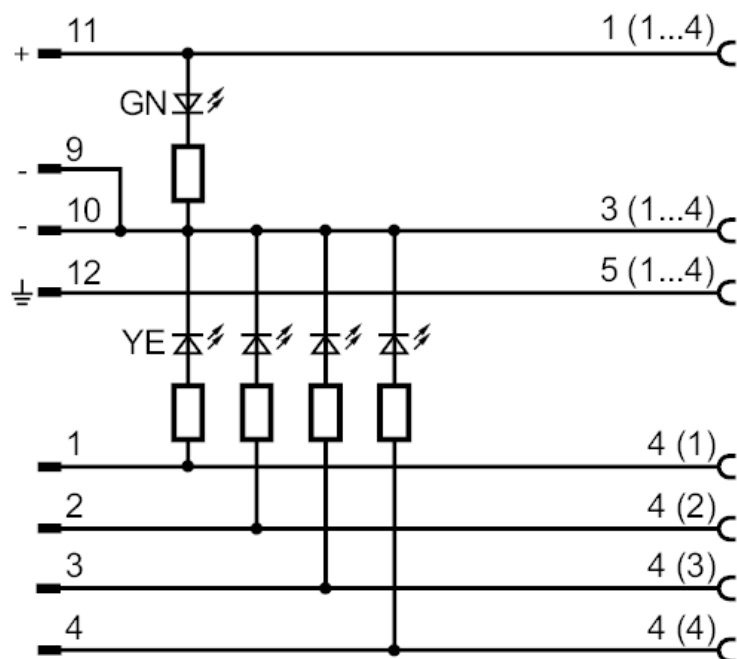

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

