




## Splitter box

ZDO4H050MSS0000-00STAK190MSS

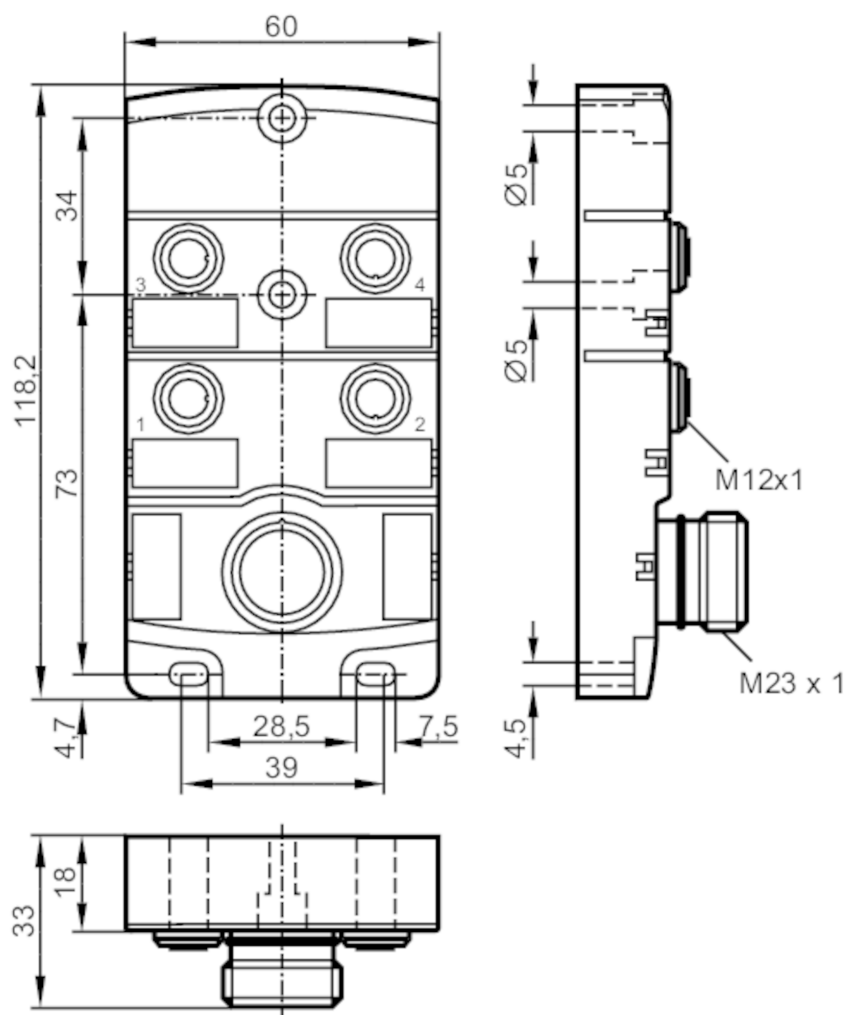

## Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Free from silicone | yes                                      |

## Electrical data

|                                   |     |                                      |
|-----------------------------------|-----|--------------------------------------|
| Operating voltage                 | [V] | < 30 DC; ("supply class 2" to cULus) |
| Max. current load per module/slot | [A] | 4                                    |
| Max. current load total           | [A] | 10                                   |

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...80 |
|---------------------|------|----------|



## Splitter box

ZDO4H050MSS0000-00STAK190MSS

|            |       |
|------------|-------|
| Protection | IP 67 |
|------------|-------|

### Tests / approvals

|             |                |        |
|-------------|----------------|--------|
| UL approval | Enclosure type | Type 1 |
|-------------|----------------|--------|

### Mechanical data

|                              |      |                 |
|------------------------------|------|-----------------|
| Weight                       | [g]  | 226.5           |
| Dimensions                   | [mm] | 33 x 60 x 118.2 |
| Materials                    |      | PA              |
| Moulded-body material        |      | PA              |
| Number of ports splitter box |      | 4               |
| Connector type               |      | M12             |

### Аксессуары


|                |                     |
|----------------|---------------------|
| Items supplied | захисні заглушки: 2 |
|                | labels: 4           |

### Remarks


|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

### Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

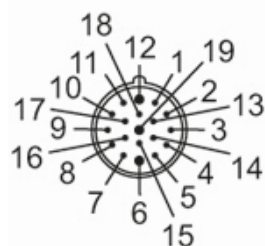

### Connection

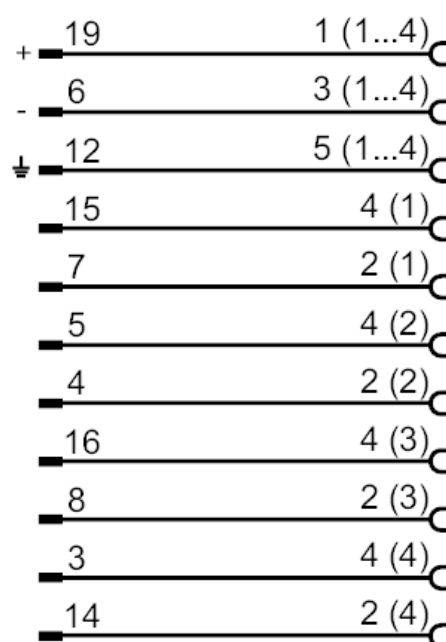



## Splitter box

ZDO4H050MSS0000-00STAK190MSS

### Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

