




Splitter box

ZDO8H050MSS0000-00STAK190MSS

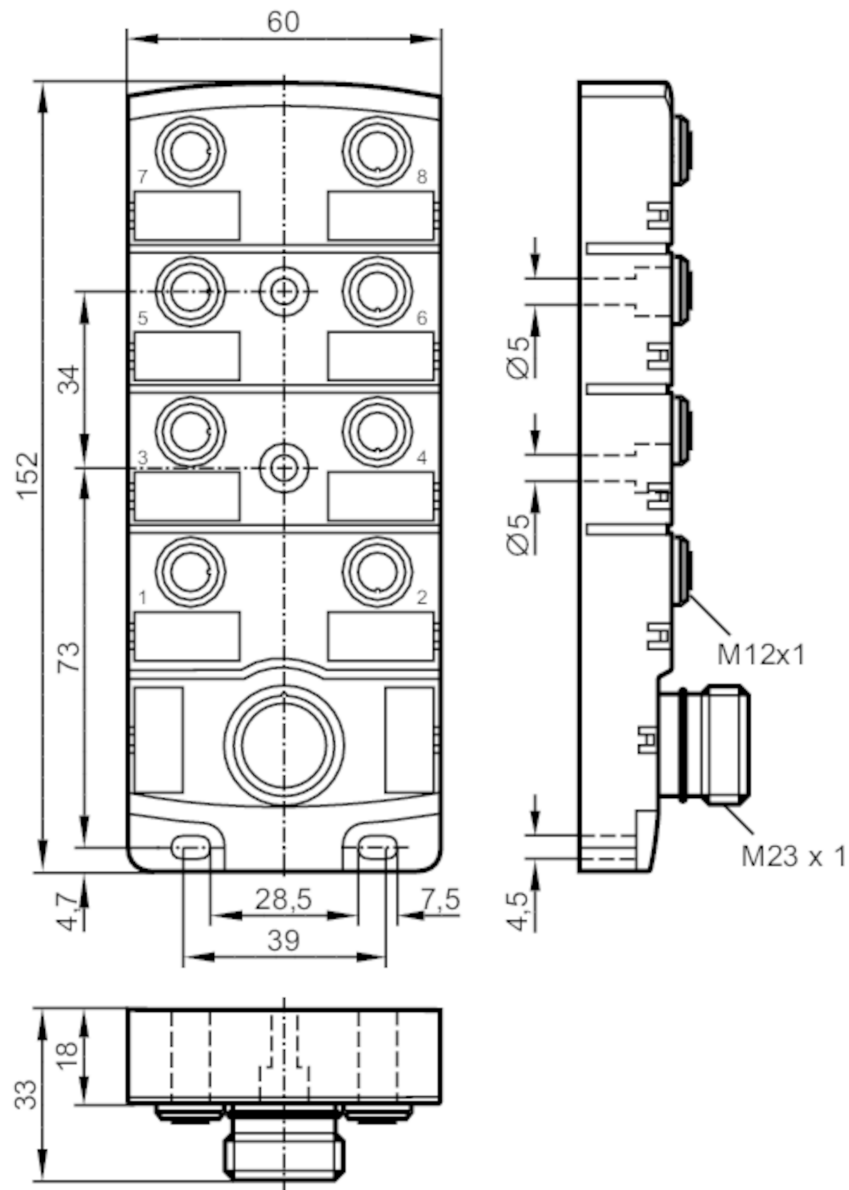

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10

Operating conditions

Ambient temperature	[°C]	-25...80
---------------------	------	----------



Splitter box

ZDO8H050MSS0000-00STAK190MSS

Protection	IP 67
------------	-------

Tests / approvals

UL approval	Enclosure type	Type 1
-------------	----------------	--------

Mechanical data

Weight	[g]	303.5
Dimensions	[mm]	33 x 60 x 152
Materials		PA
Moulded-body material		PA
Number of ports splitter box		8
Connector type		M12

Аксессуары


Items supplied	захисні заглушки: 2
	labels: 8

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection

Connector: 1 x M23; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

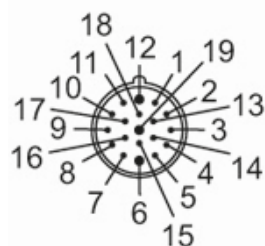

Connection

+	19	1 (1...8)
-	6	3 (1...8)
±	12	5 (1...8)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)
	11	4 (7)
	10	2 (7)
	1	4 (8)
	18	2 (8)



Splitter box

ZDO8H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

