




Splitter box

ZDO4F035MSJ0000---STGH080MSJ

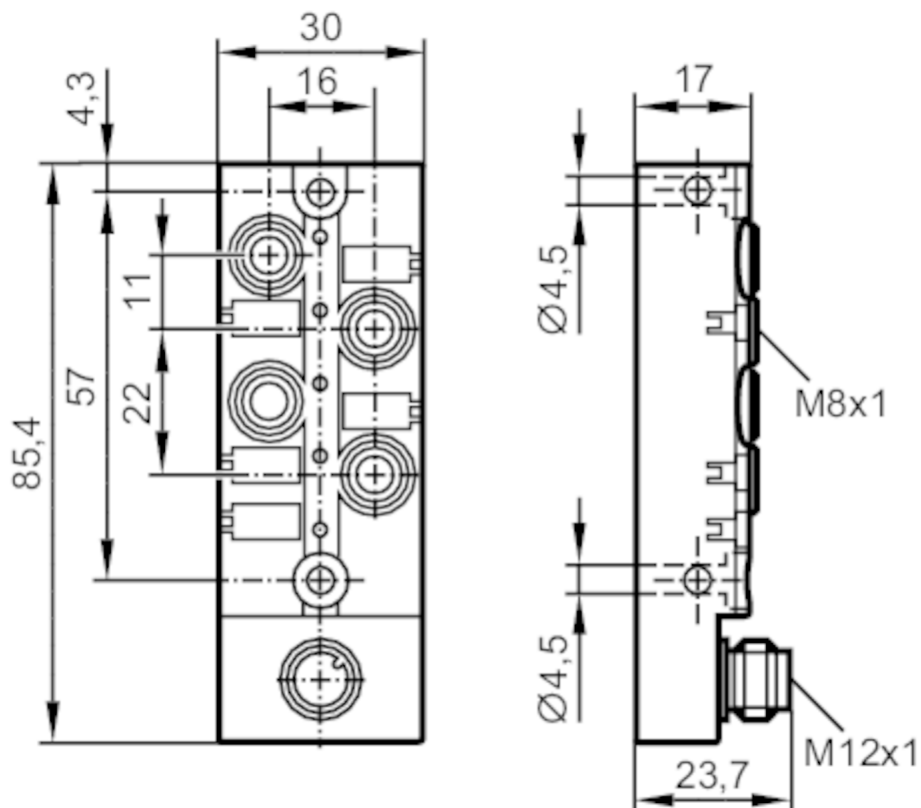

Application		
Special feature	Gold-plated contacts	
Electrical data		
Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	2
Outputs		
Electrical design	NPN	
Operating conditions		
Ambient temperature	[°C]	-25...80
Ambient temperature (moving)	[°C]	-5...60
Protection	IP 65; IP 67; IP 68; (1 m / 7 days)	
Mechanical data		
Weight	[g]	88
Dimensions	[mm]	23.7 x 30 x 85.4
Materials	PBT-GF20; brass nickel-plated	
Moulded-body material	PBT-GF 20 / brass, nickel-plated	
Number of ports splitter box	4	




Splitter box

ZDO4F035MSJ0000---STGH080MSJ


Connector type		M8
Displays / operating elements		
Display	switching status	4 x LED, yellow
	operation	1 x LED, green
Аксессуары		
Accessories (optional)	DIN rail adapter:, E73006	
	Protective cap: M8, E73005	
Remarks		
Pack quantity	1 pcs.	

Electrical connection - Connection

Connector: 1 x M12; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

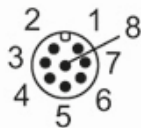

Connection

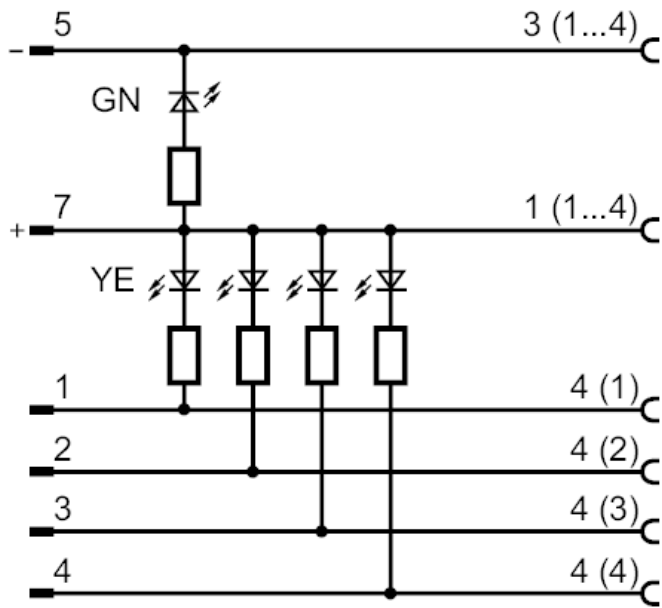



Splitter box

ZDO4F035MSJ0000---STGH080MSJ

Electrical connection - slot

Connector: 4 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

