




Splitter box

ZDO4F049MSJ0000---STGO120MSJ

Article no longer available - archive entry

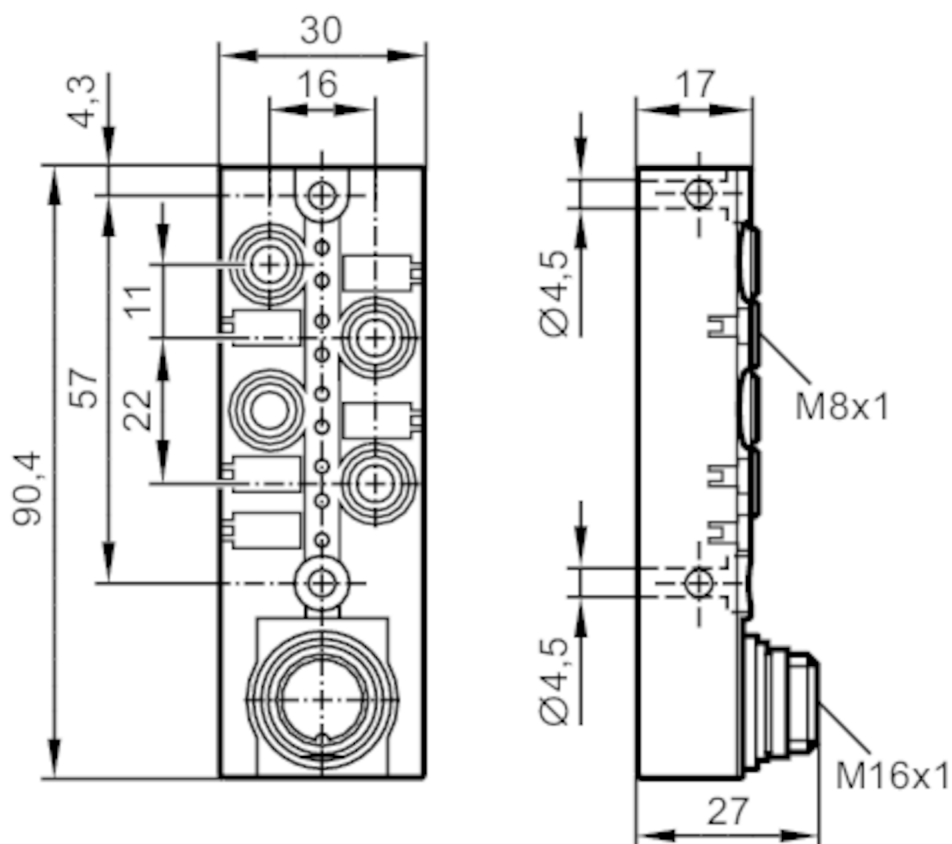

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage	[V]	10...30 DC; ("supply class 2" to cULus)
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	6

Outputs

Electrical design

NPN

Operating conditions

Ambient temperature	[°C]	-25...80
Ambient temperature (moving)	[°C]	-5...60
Protection		IP 67; IP 68; (1 m / 7 days)



Splitter box


ZDO4F049MSJ0000---STGO120MSJ

Mechanical data		
Weight	[g]	109
Dimensions	[mm]	27 x 30 x 90.4
Materials		PBT-GF20; brass nickel-plated
Moulded-body material		PBT-GF 20 / brass, nickel-plated
Number of ports splitter box		4
Connector type		M8
Displays / operating elements		
Display	switching status	8 x LED, yellow
	operation	1 x LED, green
Аксессуары		
Accessories (optional)		DIN rail adapter:, E73006
		Protective cap: M8, E73005
Remarks		
Pack quantity		1 pcs.
Electrical connection - Connection		
Connector: 1 x M16; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated		

Splitter box

ZDO4F049MSJ0000---STGO120MSJ

Connection

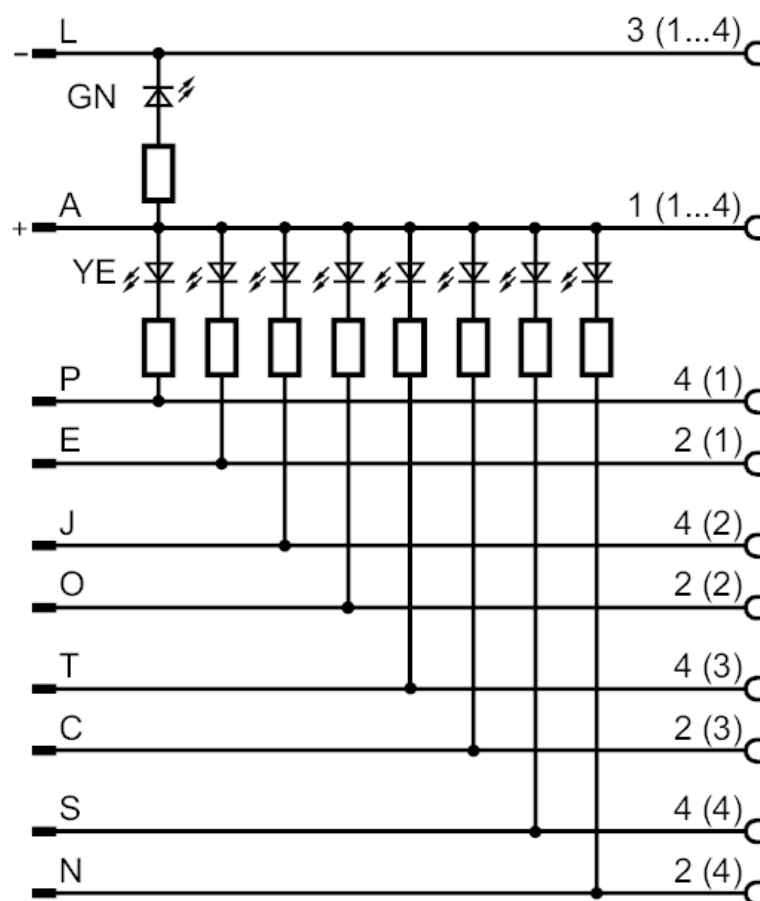

Electrical connection - slot

Connector: 4 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated

