


Splitter box

ZDO8F039MSS0000---STGH120MSS

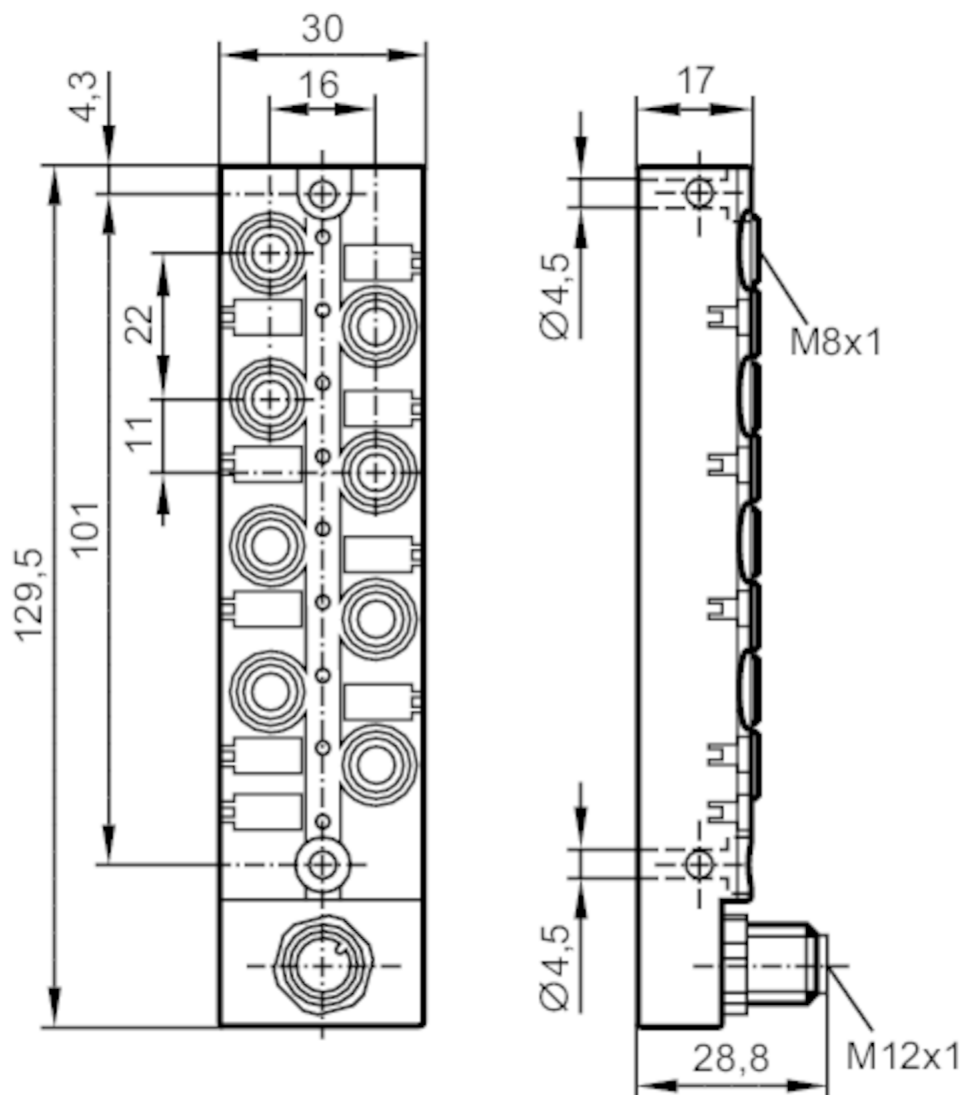

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage	[V]	15...30 DC; ("supply class 2" to cULus)
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	2

Outputs

Electrical design

PNP

Operating conditions

Ambient temperature

[°C]

-25...80



Splitter box

ZDO8F039MSS0000---STGH120MSS

Ambient temperature (moving)	[°C]	-5...60
Protection	IP 67; IP 68; (1 m / 7 days)	

Mechanical data

Weight	[g]	128.5
Materials	PBT-GF20; brass nickel-plated	
Moulded-body material	PBT-GF 20 / brass, nickel-plated	
Number of ports splitter box	8	
Connector type	M8	

Displays / operating elements

Display	switching status	8 x LED, yellow
	operation	1 x LED, green

Аксессуары


Accessories (optional)	Protective cap: M8, E73005
------------------------	----------------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - Connection


Connector: 1 x M12; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

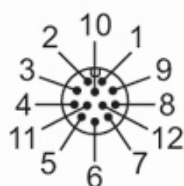

Splitter box

ZDO8F039MSS0000---STGH120MSS

Connection

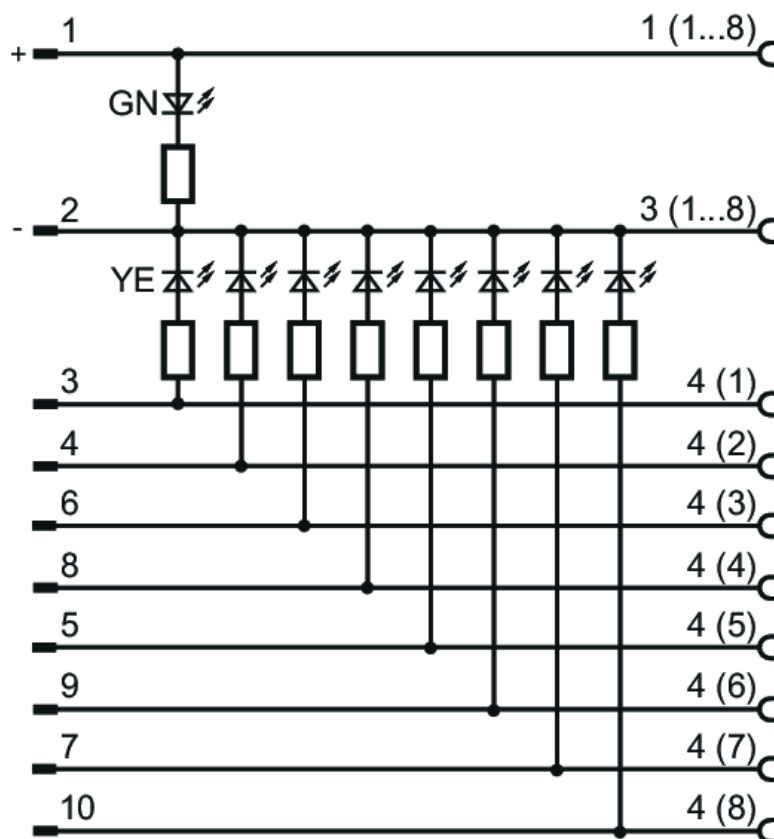

Electrical connection - slot

Connector: 8 x M8; coding: A; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

