





Y connection cable

Cable/Plug&Play/M12/0.6m

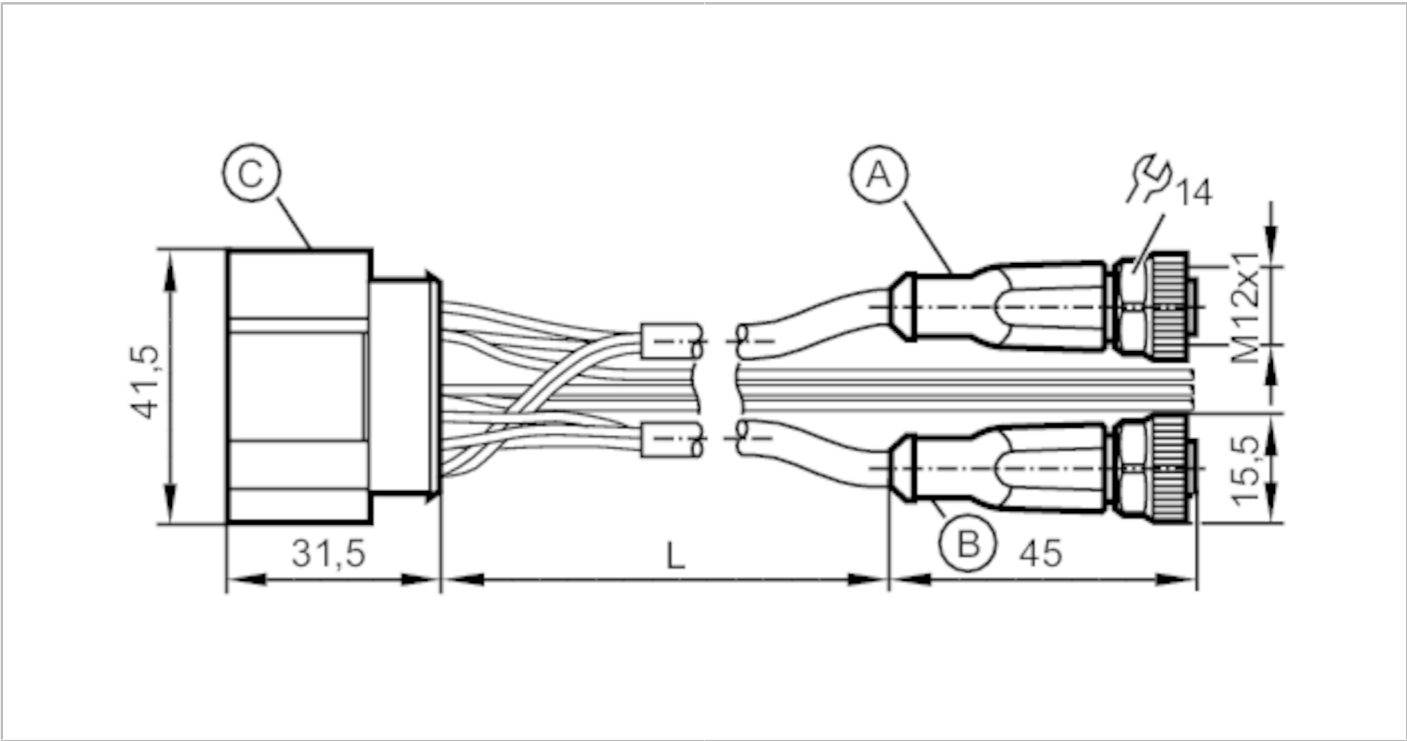

Application		
Design		Adapter cable
Electrical data		
Operating voltage	[V]	8...32 DC
Operating conditions		
Ambient temperature	[°C]	-20...85
Mechanical data		
Weight	[g]	109
Materials		housing: PBT black; socket: TPU orange; Sealing: Viton
Remarks		
Pack quantity		1 pcs.
Electrical connection - C		

Connector: 1 x AMP connector, straight

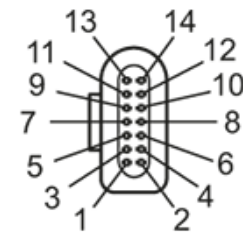

Electrical connection	
Cable: 0.6 m, PUR, black, Ø 5.1 mm; 5 x 0.5 mm²	
Cable: 0.6 m, PUR, black, Ø 4.9 mm; 3 x 0.5 mm²	

EC3148




Y connection cable

Cable/Plug&Play/M12/0.6m


Cable: 0.6 m; 2 x 0.5 mm²

Connection

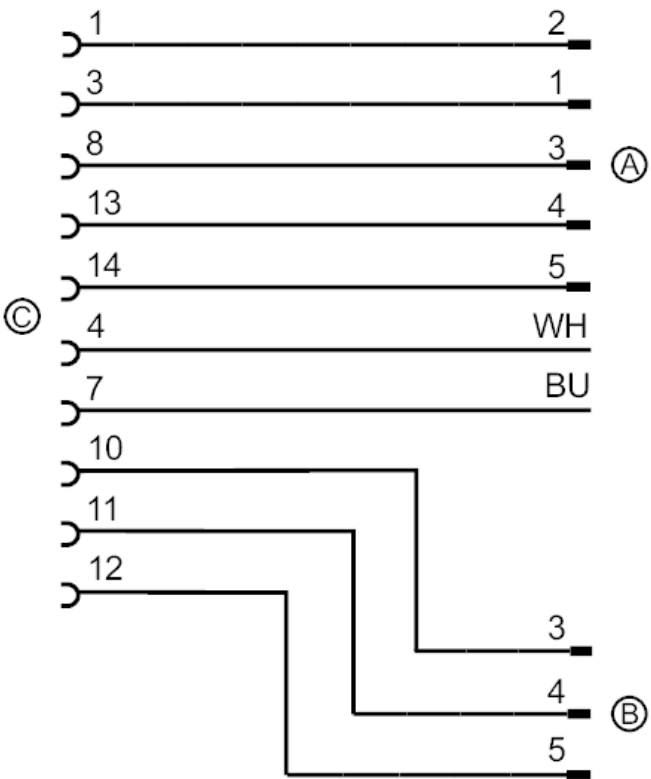

Electrical connection - A

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

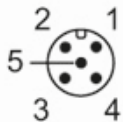

Electrical connection - B

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

