


## Y connection cable

YDOGH034MSS00,3H03STGH040MSS

Please see the technical note under "Downloads"

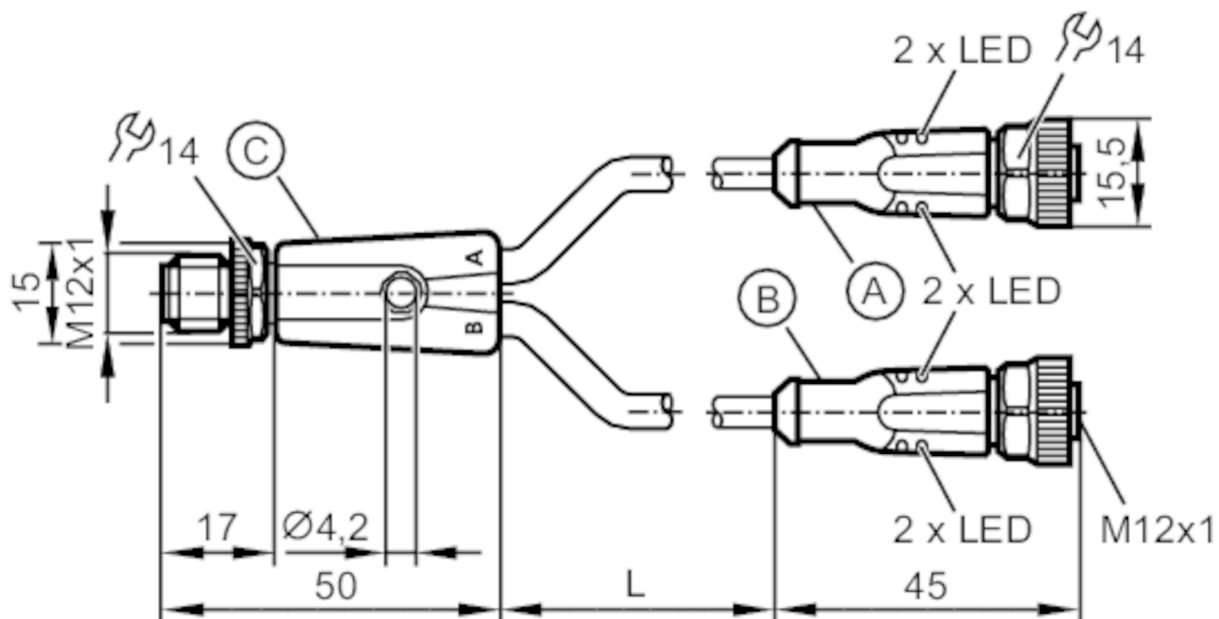

## Application

|                    |                                                                                |
|--------------------|--------------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone | yes                                                                            |

## Electrical data

|                             |            |
|-----------------------------|------------|
| Operating voltage [V]       | 10...36 DC |
| Protection class            | II         |
| Max. current load total [A] | 4          |

## Outputs

|                   |     |
|-------------------|-----|
| Electrical design | PNP |
|-------------------|-----|

## Operating conditions

|                                      |                             |
|--------------------------------------|-----------------------------|
| Ambient temperature [°C]             | -25...90                    |
| Note on ambient temperature          | cULus: ...75 °C             |
| Ambient temperature (moving) [°C]    | -25...90                    |
| Note on ambient temperature (moving) | cULus: ...75 °C             |
| Protection                           | IP 65; IP 67; IP 68; IP 69K |

## Mechanical data

|                       |                      |
|-----------------------|----------------------|
| Weight [g]            | 69                   |
| Moulded-body material | TPU                  |
| Material nut          | brass, nickel-plated |
| Sealing material      | FKM                  |

# EVC682



## Y connection cable

YDOGH034MSS00,3H03STGH040MSS

|                              |                                 |                                                                                    |
|------------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Number of ports splitter box | 2                               |                                                                                    |
| Drag chain suitability       | yes                             |                                                                                    |
| Drag chain suitability       | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                              | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                              | bending cycles                  | > 5 Mio.                                                                           |
|                              | torsional strain                | ± 180 °/m                                                                          |

### Displays / operating elements

|         |                  |                 |
|---------|------------------|-----------------|
| Display | switching status | 2 x LED, yellow |
|         | operation        | 2 x LED, green  |

### Remarks

|               |                                                 |  |
|---------------|-------------------------------------------------|--|
| Notes         | Please see the technical note under "Downloads" |  |
| Pack quantity | 1 pcs.                                          |  |

### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm )

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, orange; Locking: brass, nickel-plated; Contacts: gold-plated;  
Tightening torque: 0.6...1.5 Nm






## Y connection cable

YDOGH034MSS00,3H03STGH040MSS


### Electrical connection

#### Connection

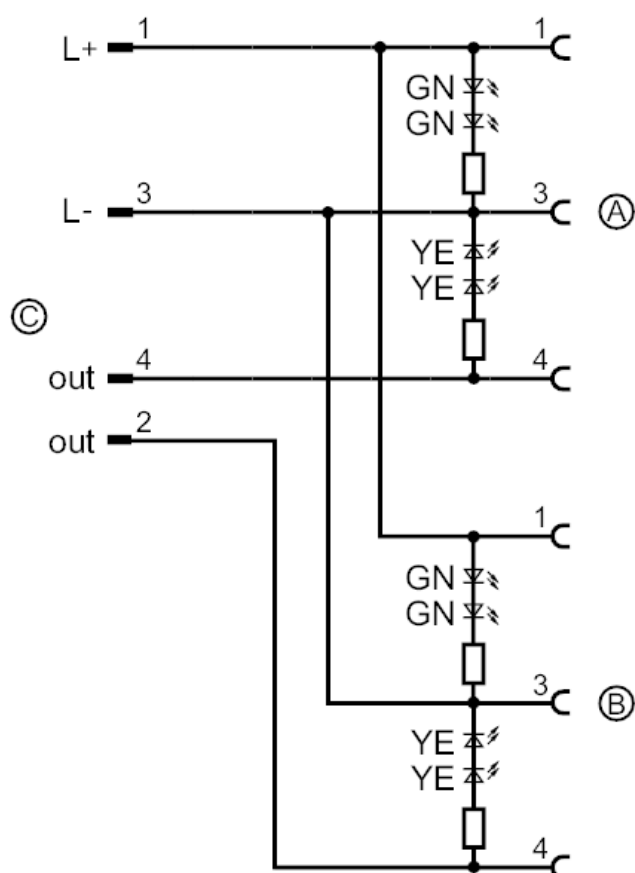

### Electrical connection - socket

Connector: 2 x M12, straight; coding: A; Moulded body: TPU, black transparent; Locking: brass, nickel-plated; Sealing: FKM; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

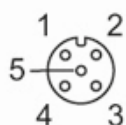




## Y connection cable

YDOGH034MSS00,3H03STGH040MSS

### Diagrams and graphs

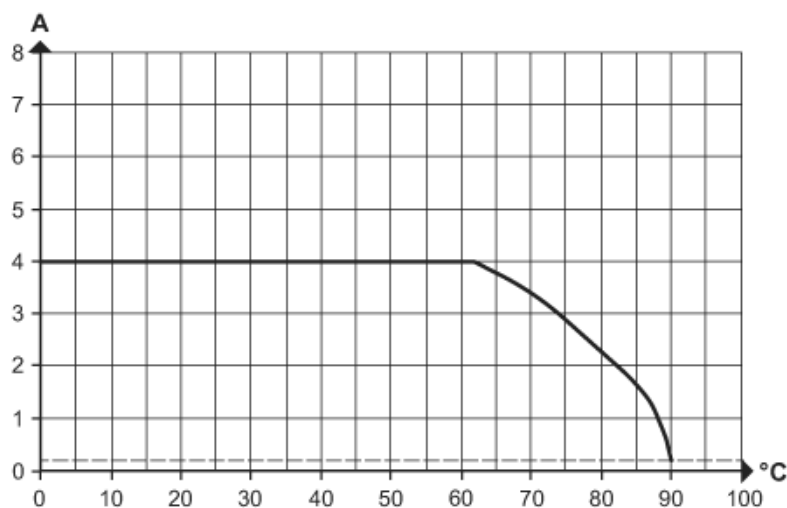

Derating  $I_{max} * 0.8$  DIN EN 60512-5-2

X Ambient temperature [°C]

Y Current [A]