




Connection cable

VDOGH040MSP0005H04STAH040MSP

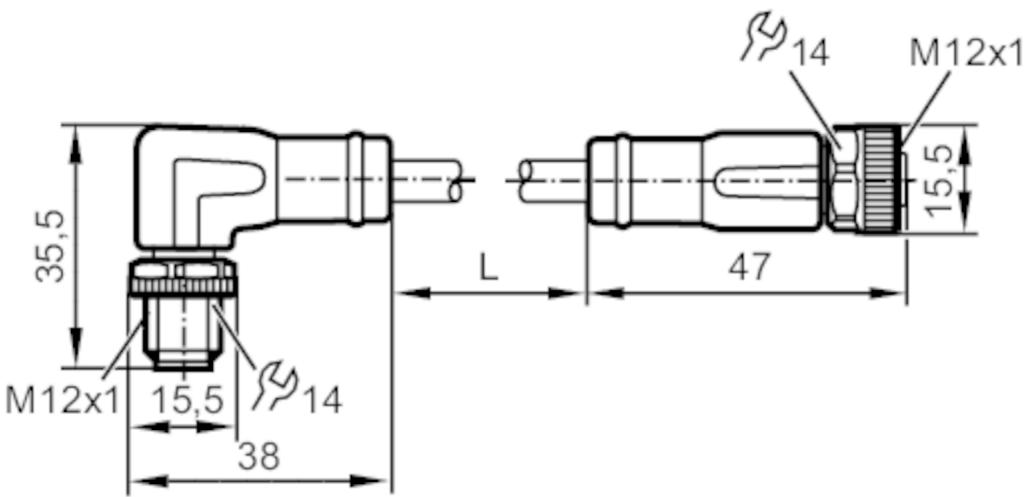

| Application                                                     |      |                                                                                |
|-----------------------------------------------------------------|------|--------------------------------------------------------------------------------|
| Special feature                                                 |      | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone                                              |      | yes                                                                            |
| Electrical data                                                 |      |                                                                                |
| Operating voltage                                               | [V]  | < 250 AC / < 300 DC                                                            |
| Protection class                                                |      | II                                                                             |
| Max. current load total                                         | [A]  | 4                                                                              |
| Operating conditions                                            |      |                                                                                |
| Ambient temperature                                             | [°C] | -25...90                                                                       |
| Ambient temperature (moving)                                    | [°C] | -25...90                                                                       |
| Storage temperature                                             | [°C] | -25...55                                                                       |
| Storage humidity                                                | [%]  | 10...100                                                                       |
| Other climatic conditions for storage according to stated class |      | 1K22/ DIN 60721-3-1                                                            |
| Protection                                                      |      | IP 65; IP 67; IP 68; IP 69K                                                    |
| Mechanical data                                                 |      |                                                                                |
| Weight                                                          | [g]  | 357.7                                                                          |
| Dimensions                                                      | [mm] | 35.5 x 15.5 x 38                                                               |
| Materials                                                       |      | housing: TPU orange; Sealing: FKM                                              |
| Material nut                                                    |      | brass, nickel-plated                                                           |
| Drag chain suitability                                          |      | yes                                                                            |



Connection cable

VDOGH040MSP0005H04STAH040MSP

|                        |                                 |                                                                                    |
|------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | bending cycles                  | > 5 Mio.                                                                           |
|                        | torsional strain                | ± 180 °/m                                                                          |

Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug


Connector: 1 x M12, angled; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm



Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 6.2 mm; 4 x 1.00 mm² (32 x Ø 0.2 mm )

Connection

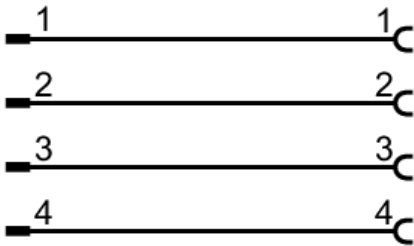

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

