




## Connection cable

VDOGF040MSS00,3H03STGF030MSS

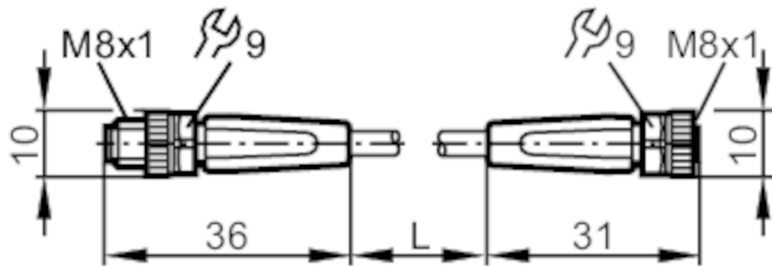

### Application

|                    |                                                                                |
|--------------------|--------------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone | yes                                                                            |

### Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 50 AC / < 60 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

### Operating conditions

|                                      |      |                             |
|--------------------------------------|------|-----------------------------|
| Ambient temperature                  | [°C] | -25...90                    |
| Note on ambient temperature          |      | cULus: ...80 °C             |
| Ambient temperature (moving)         | [°C] | -25...90                    |
| Note on ambient temperature (moving) |      | cULus: ...80 °C             |
| Protection                           |      | IP 65; IP 67; IP 68; IP 69K |

### Mechanical data

|                        |                                 |                                                                                    |
|------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Weight                 | [g]                             | 25.5                                                                               |
| Materials              |                                 | housing: TPU orange; Sealing: FKM                                                  |
| Material nut           |                                 | brass, nickel-plated                                                               |
| Drag chain suitability |                                 | yes                                                                                |
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                        | bending cycles                  | > 5 Mio.                                                                           |
|                        | torsional strain                | ± 180 °/m                                                                          |

# EVC270



## Connection cable

VDOGF040MSS00,3H03STGF030MSS

### Remarks

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 3.7 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

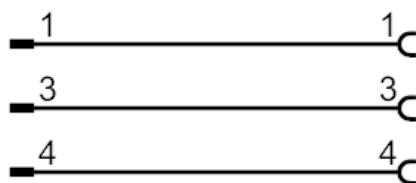

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm

