




Y connection cable

YDSGHDA0VAS0010PDASTGH030VAS

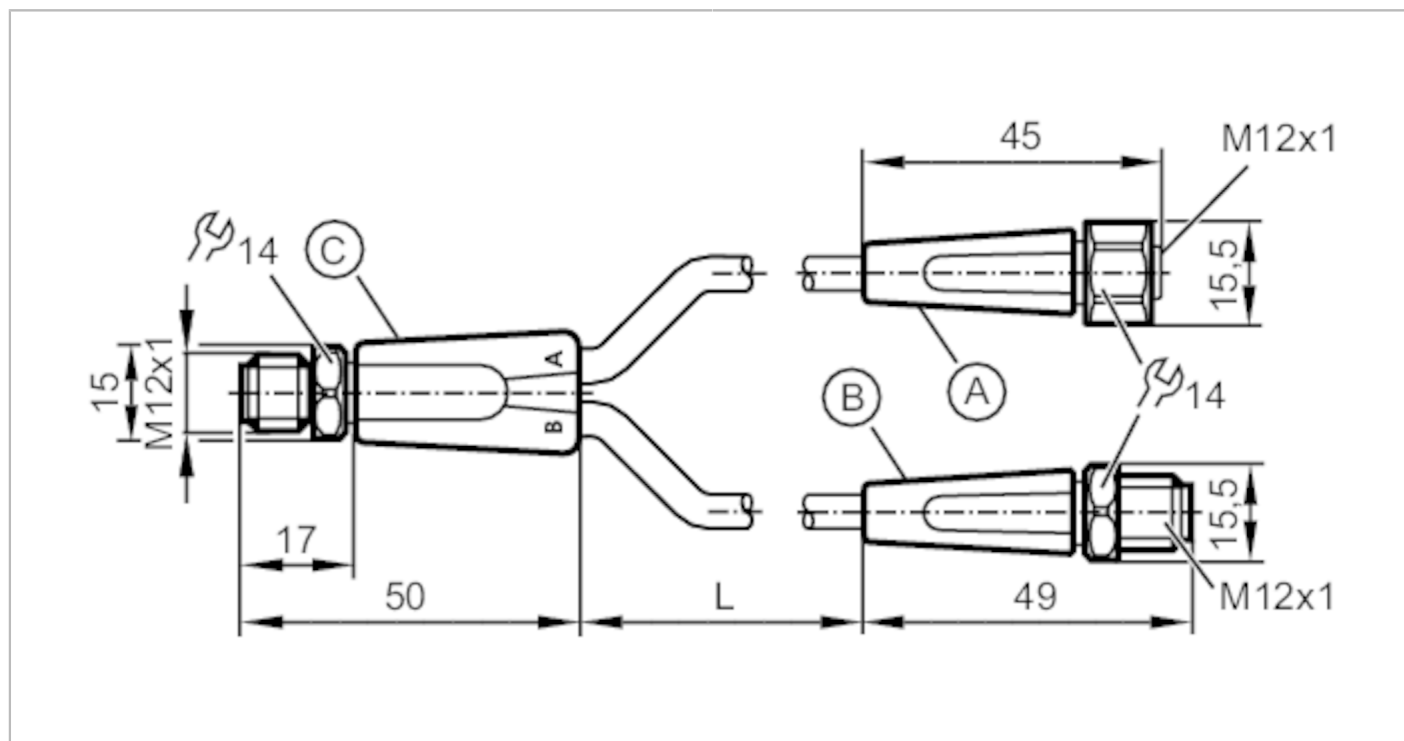

Application		
Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability	
Application	hygienic and wet areas in the food industry	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 24 DC
Protection class	III	
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-25...100
Protection	IP 65; IP 67; IP 68; IP 69K	
Mechanical data		
Weight	[g]	633.5
Moulded-body material	PP	
Material nut	stainless steel (1.4404 / 316L)	
Sealing material	EPDM	
Number of ports splitter box	2	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	bending cycles	> 5 Mio.
	torsional strain	± 180 °/m



Y connection cable

YDSGHDA0VAS0010PDASTGH030VAS

Remarks

Pack quantity

1 pcs.

Electrical connection

Cable: 10 m, MPPE, Halogen-free, grey, Ø 4.9 mm; 2 x 0.34 mm² (42 x Ø 0.1 mm) + 5 x 0.34 mm² (42 x Ø 0.1 mm)


Electrical connection - plug C

Connector: 1 x M12, straight; coding: A; Moulded body: PP, grey; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.2 Nm



Electrical connection - socket A

Connector: 1 x M12, straight; coding: A; Moulded body: PP, grey; Locking: stainless steel (1.4404 / 316L); Sealing: EPDM; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

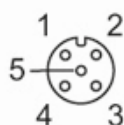

Electrical connection - plug B

Connector: 1 x M12, straight; coding: A; Moulded body: PP, grey; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm





Y connection cable

YDSGHDA0VAS0010PDASTGH030VAS

Electrical connection - Connection

Connection

